

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972

<https://www.phoenixcontact.com/us/products/1419972>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B10, for double locking latch, material: Die-cast aluminum, salt water resistant, variable, height: 57 mm, cable gland: none, Standard, Without thread opening for screw connection

## Product description

Sleeve housing, without screw thread

## Your advantages

- Good shielding in the event of electromagnetic interference

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1419972             |
| Packing unit                         | 1 pc                |
| Minimum order quantity               | 1 pc                |
| Sales key                            | BF56                |
| Product key                          | BF7APB              |
| Catalog page                         | Page 610 (C-2-2019) |
| GTIN                                 | 4055626201320       |
| Weight per piece (including packing) | 154.4 g             |
| Weight per piece (excluding packing) | 154.4 g             |
| Customs tariff number                | 85389099            |
| Country of origin                    | CN                  |

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972

<https://www.phoenixcontact.com/us/products/1419972>

## Technical data

### Notes

|         |                                                                                          |
|---------|------------------------------------------------------------------------------------------|
| General | for contact inserts HC-B10, BB18, DD42, M, K8/24, HV03                                   |
| General | also available as a powder-coated or color version: 1372748 HC-STA-B10-HLFD-BLANK-EL/... |

 
### Product properties

|                     |                            |
|---------------------|----------------------------|
| Product type        | Housing with locking latch |
| Housing type        | Sleeve housing             |
| Application         | Standard                   |
| Type                | B10                        |
| Type                | Low design                 |
| Cable outlet        | variable                   |
| Pg screw connection | none                       |

### Data management status

|                  |    |
|------------------|----|
| Article revision | 02 |
|------------------|----|

### Dimensions

|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 44 mm                                                                                |
| Height              | 57 mm                                                                                |
| Length              | 73 mm                                                                                |

### Material specifications

|                          |                                         |
|--------------------------|-----------------------------------------|
| Housing material         | Die-cast aluminum, salt water resistant |
| Housing surface material | uncoated                                |

### Mechanical properties

#### Mechanical data

|              |     |
|--------------|-----|
| Locking type | Pin |
|--------------|-----|

### Environmental and real-life conditions

#### Ambient conditions

|                         |             |
|-------------------------|-------------|
| Degree of protection    | IP66        |
|                         | IP67        |
| Enclosure rating (NEMA) | 4 (UL 50e)  |
|                         | 4X (UL 50e) |
|                         | 12 (UL 50e) |

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972

<https://www.phoenixcontact.com/us/products/1419972>

|                                 |                   |
|---------------------------------|-------------------|
| Impact strength                 | IK09              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing


1419972

<https://www.phoenixcontact.com/us/products/1419972>



## Drawings

Dimensional drawing

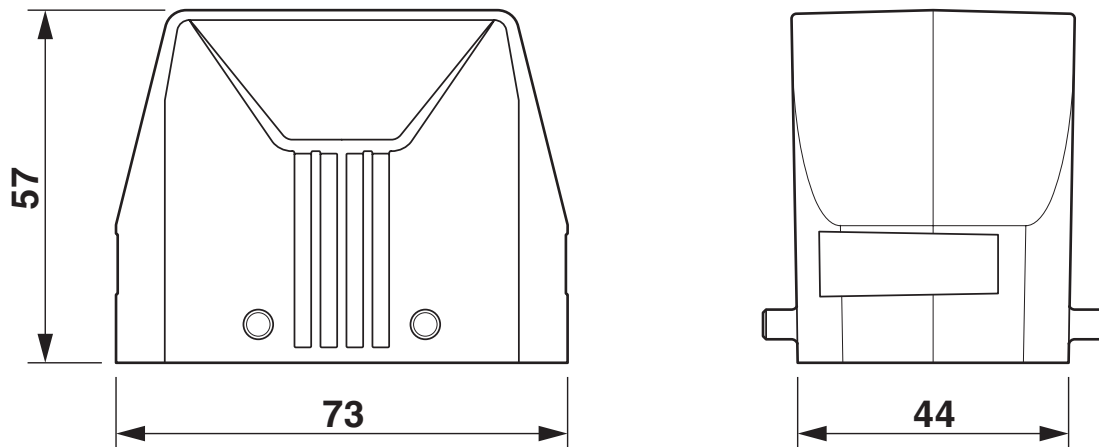

Dimensional drawing

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972

<https://www.phoenixcontact.com/us/products/1419972>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419972>

**DNV**

Approval ID: TAE000037S



**EAC**

Approval ID: RU C-DE.AI30.B.01102



**EAC**

Approval ID: RU C-DE.BL08.B.00511

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972

<https://www.phoenixcontact.com/us/products/1419972>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27440202 |
| ECLASS-12.0 | 27440202 |
| ECLASS-13.0 | 27440202 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000437 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-STA-B10-HLFD-BLANK-EL-AL - Housing



1419972  
<https://www.phoenixcontact.com/us/products/1419972>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)