


PXP9012/08/S Datasheet

Product Name // PXP9012/08/S

 [View Product Page](#)

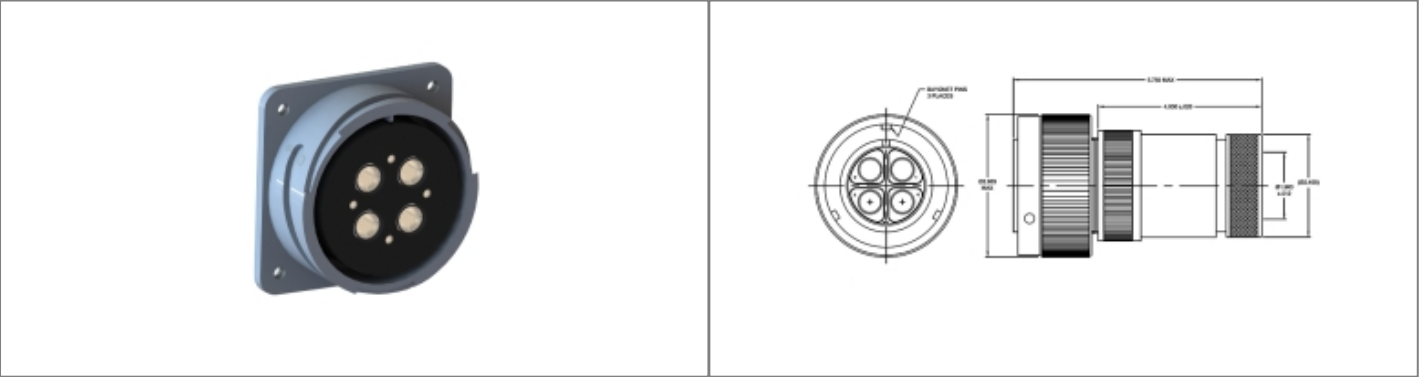

// Product Description:

- Male and Female Connectors
 - Water and dustproof to IP68 when mated with compatible connector
 - 2, 4, 6, 8, 11 Contact options
- Bayonet Quarter Turn Lock
 - High Amperage 13A, 80A, High Voltage 1250VAC

// General Information:

Product Display Title:	9000 Series Buccaneer Connectors
Product Family:	Circular Power Connectors
Product Series:	9000 Series High Power Buccaneer
Body Material:	Delrin
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Current Max:	80A
Diameter Over Coupling Ring Mm:	72mm
Function:	Flange Mount Connector
Ip Rating:	IP68
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	8 Contacts
Voltage Max:	1250V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)