


PX0921/10/S Datasheet

Product Name // Inline Cable Connector PX0921 Series 10
Contact Socket 13mm-15mm Cable (Yellow Gland)

 [View Product Page](#)

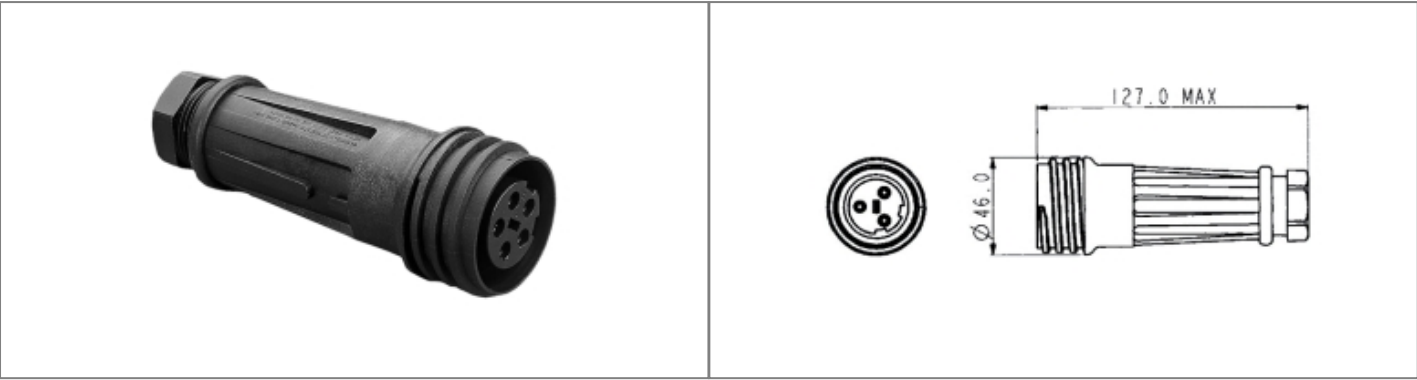

// Product Description:

Inline Cable Connectors

Water and dustproof to IP68 when mated with compatible connector

Positive fast-acting locking ring - can be turned with a gloved hand

Plug or Socket

2, 3, 4, 5, 7, 10 Contact with leading Earth on 3, 4, 5, 7 Contact versions, trailing Neutral on 5 Contact version

Screw Terminals

Choice of cable acceptance 7mm-22mm diameter depending on part code (see data for details):

PX09 part codes 7mm-15mm diameter

PXA9 part codes (large cable version with strain relief clamp) 14mm-22mm diameter

Packs of Cable Glands for differing cable diameters available separately (PX0980, PXA980)

PX0970/PX0991 Sealing Caps available separately to maintain IP rating of unmated connectors

Mate with PX0911 or PXA911 Series Flex Connectors, as appropriate

// General Information:

Product Display Title:

Product Family:

Product Series:

Approvals:

Body Material:

Body Material Type:

Contact Type:

Coupling Type:

Current Max:

Diameter Over Coupling Ring Mm:

Flamability Rating:

Function:

Ip Rating:

Max Cable Entry Size:

Min Cable Entry Size:

Max Contact Accomodation Awg:

Min Contact Accomodation Awg:

Max Contact Accomodation Mm2:

Min Contact Accomodation Mm2:

Max Operating Temperature:

Min Operating Temperature:

Number Of Contacts:

Voltage Max:

Inline Cable Connectors

Circular Power Connectors

900 Series Buccaneer

UL

Polyamide (PA)

Plastic Body

Socket Contact

Screw

10A

58mm

UL94V-0

Inline Cable Connector

IP68

15mm

13mm

18AWG

14AWG

2.5mm2

0.75mm2

+85°C

-40°C

10 Contacts

250V

// Product PDF Links



900 Series power connectors...



900 Series power connectors wiring...

// Product 3D CAD Model Links



PX0921/10/S3D CAD Model

 Have a question or project enquiry you'd like to talk to us about?

 [Click Here To Contact Us](#)

Bulgin Datasheets

1