



MS27470

Jam Nut Mount Hermetic Receptacle
MIL-DTL-38999 Series I

How To Order: MS

Shell Style

MS27470 - Jam Nut Mount, Series I

Connector Material / Finish

D - Carbon Steel - Fused Tin Finish
E - Stainless Steel - Passivate Finish
N - Stainless Steel - Nickel Finish

Contact Termination

P - Pin, Solder Cup **S** - Socket, Solder Cup
X - Pin, Eyelet **Z** - Socket, Eyelet
C - Pin, PCB **D** - Socket, PCB
 Flex Feedthrough Flex Feedthrough

Class

Y - Hermetic

MS27470

Y

11

N

35

P




A

Shell Size

9, 11, 13, 15, 17, 19, 21, 23, 25

Insert Arrangement
 MIL-DTL-38999 Series I
 Hermetic Inserts Per
 MIL-STD-1560;
 See Pages B-2 - B-4

**Alternate Key
 Position**
A, B, C, D
(Omit for Normal)

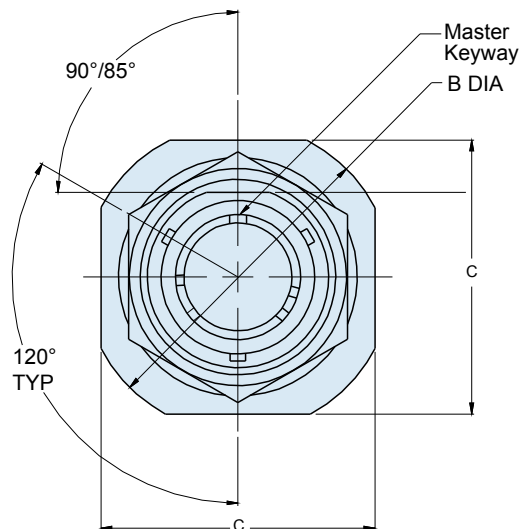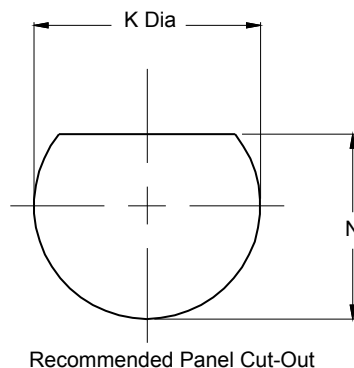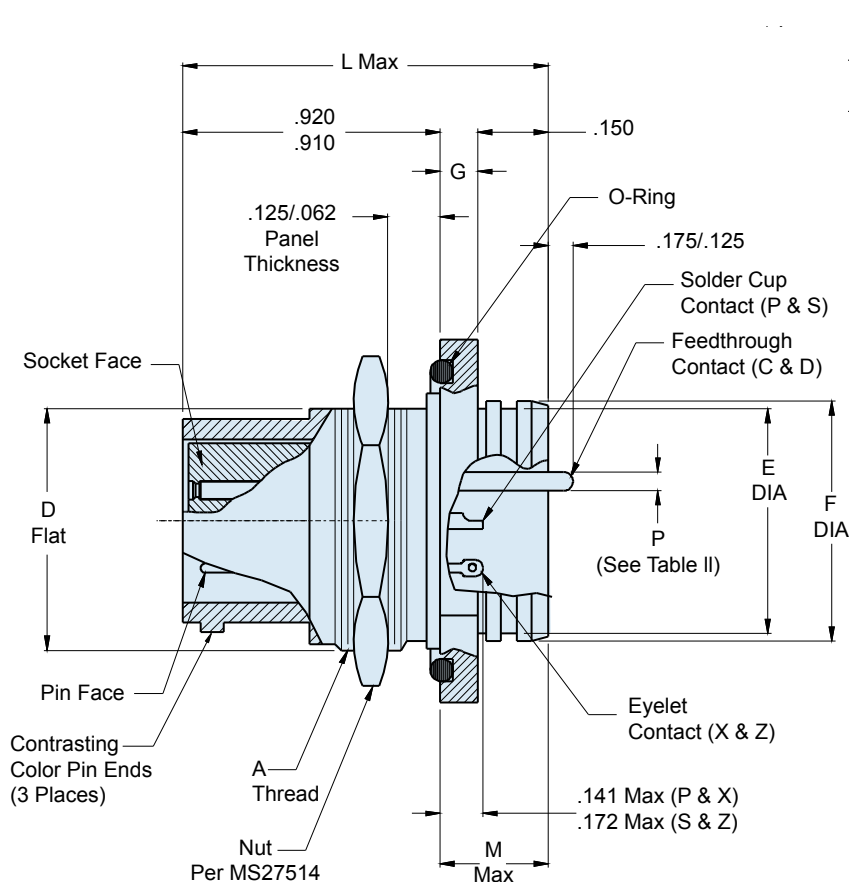

Dimensions in Inches (millimeters) are subject to change without notice.

© 2013 Glenair, Inc.

U.S. CAGE Code 06324

Printed in U.S.A.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Glenair:

[MS27470Y15N35C](#) [MS27470Y17N26C](#) [MS27470Y17N35C](#) [MS27470Y11E35C](#) [MS27470Y15E18C](#)
[MS27470Y23E53C](#) [MS27470Y13D35C](#) [MS27470Y17E26C](#) [MS27470Y25E35CA](#)