


MS/Standard

MS3102A or C

box mounting receptacle

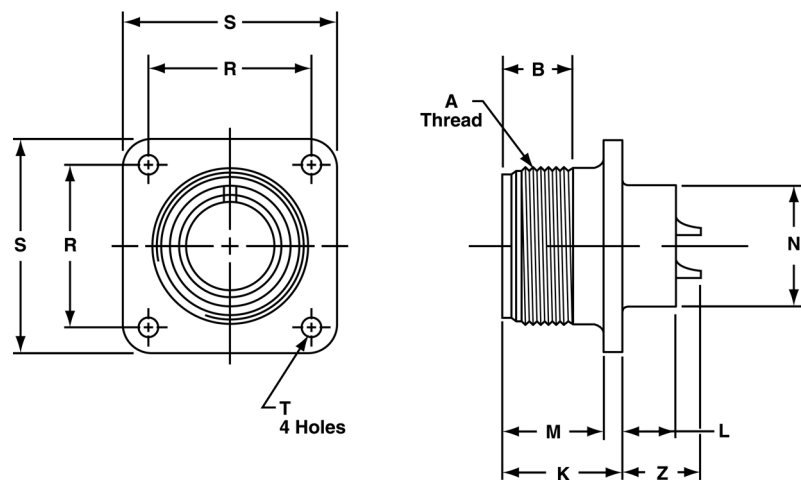

To complete order number, see "how to order" pg. 70.
For solder well data, see page 67.

Shell Size	A Thread Class 2A	B Min Full Thread	K $+.020$ $-.010$	L $+.000$ $-.010$	M $+.010$ $-.000$	N Dia. $+.010$ $-.000$	R $\pm .005$	S $\pm .031$	T Dia. $+.004$ $-.002$	Z $+.050$ $-.060$
8S	.5000-28UNEF	.391	.672	.297	.562	.375	.594	.875	.120	.422
10S	.6250-24NEF	.391	.672	.297	.562	.500	.719	1.000	.120	.422
10SL	.6250-24NEF	.391	.672	.297	.562	.625	.719	1.000	.120	.422
12S	.7500-20UNEF	.450	.672	.297	.562	.625	.812	1.094	.120	.422
12	.7500-20UNEF	.625	.860	.484	.750	.625	.812	1.094	.120	.672
14S	.8750-20UNEF	.450	.672	.297	.562	.750	.906	1.188	.120	.422
14	.8750-20UNEF	.625	.860	.484	.750	.750	.906	1.188	.120	.672
16S	1.0000-20UNEF	.450	.672	.297	.562	.875	.969	1.281	.120	.422
16	1.0000-20UNEF	.625	.860	.484	.750	.875	.969	1.281	.120	.672
18	1.1250-18NEF	.625	.891	.453	.750	1.000	1.062	1.375	.120	.641*
20	1.2500-18NEF	.625	.891	.453	.750	1.125	1.156	1.500	.120	.641*
22	1.3750-18NEF	.625	.891	.453	.750	1.250	1.250	1.625	.120	.641*
24	1.5000-18NEF	.625	.953	.453	.812	1.375	1.375	1.750	.147	.578
28	1.7500-18NS	.625	.953	.453	.812	1.625	1.562	2.000	.147	.578*
32	2.0000-18NS	.625	1.031	.438	.875	1.875	1.750	2.250	.173	.500*
36	2.2500-16UN	.625	1.031	.438	.875	2.062	1.938	2.500	.173	.500*
40	2.5000-16UN	.625	1.031	.438	.875	2.312	2.188	2.750	.173	.500*
44***	2.7500-16UN	.625	1.063	.543†	.875	2.594	2.375	3.000††	.173	.768**
48***	3.0000-16UN	.625	1.063	.543†	.875	2.812	2.625	3.250††	.209	.769**

* Increase Z dimension by .312 for size "0" contact only.

** Increase Z dimension by .062 for size "0" contact only.

*** Available in proprietary version only.

† $+.020$ $-.030$

†† $\pm .020$

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[MS3102A10SL-4PW](#) [MS3102A16-2P](#) [MS3102A16-2S](#) [MS3102A18-14P](#) [MS3102A18-14S](#) [MS3102A18-29S](#)
[MS3102A18-6P](#) [MS3102A18-7P](#) [MS3102A20-12P](#) [MS3102A20-20P](#) [MS3102A20-25P](#) [MS3102A22-21P](#)
[MS3102A22-24P](#) [MS3102A22-7S](#) [MS3102A24-17P](#) [MS3102A28-4P](#) [MS3102A32-3S](#) [MS3102A36-20P](#) [MS3102A36-](#)
[4P](#) [MS3102A36-4S](#) [MS3102A40-1P](#) [MS3102C12S-3S](#) [MS3102C16-9P](#) [MS3102C16S-8S](#) [MS3102C22-19P](#)
[MS3102C24-11P](#) [MS3102C28-16P](#)