


PXMBNI05RPM04APC Datasheet

 [View Product Page](#)

**Product Name // M5 Series A Code Brass Nickel Plated
Rear Panel Mount Connector 4 Contact Pins PCB
Termination**

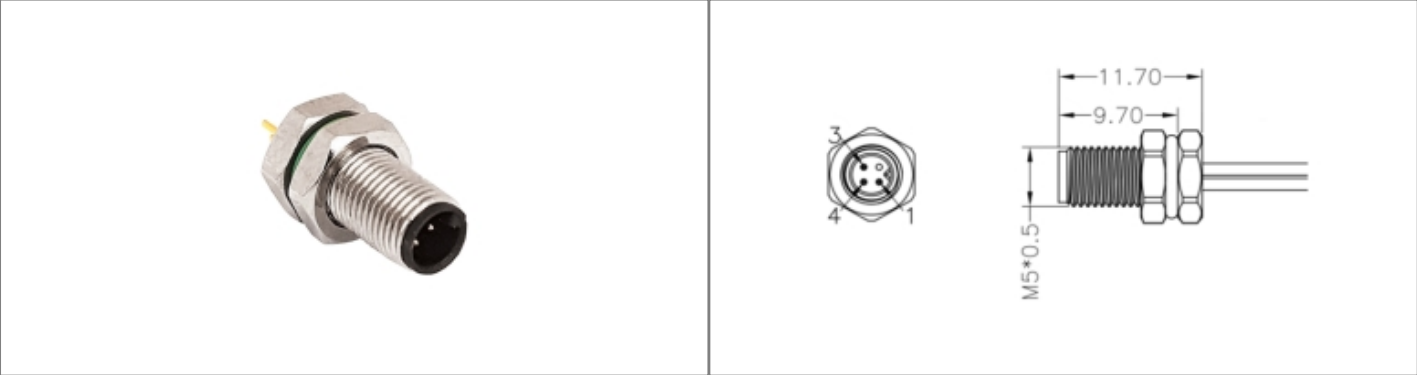

// Product Description:

- M5 Series Rear Panel Mount Connectors
- Water and dustproof to IP67 when mated with compatible connector
- A Code
- Pin or Socket
- 3, 4 Contact
- PCB Terminal or Flying Lead Termination with choice of lead lengths, depending on part code
- Mate with M5 Series Inline Body and Flex Body Connectors, depending on part code

// General Information:

Product Display Title:	M5 Series Rear Panel Mount Connectors
Product Family:	Circular Automation Connectors
Product Series:	M5 Series
Approvals:	CSA, UL
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Diameter Over Coupling Ring Mm:	6.5mm
Function:	Rear Panel Mount Connector
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	4 Contacts
Panel Cut Out:	Ø5mm
Pin Layout Code:	A Code
Thread Size:	M5 x 0.5
Voltage Max:	60V

// Product PDF Links

 [M5 Series automation connectors...](#)

// Product 3D CAD Model Links

 [PXMBNI05RPM04APC3D CAD Model](#)