



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	3
Wire Size/AWG	28 - 20
Gender	Reverse Gender
Plug	Plug - Elbow
Locking system	Push-pull
Jacket cable outside diameter [mm]	3.30 - 4.20 mm
Size	0B
Series	B - Indoor keyed

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsj-0b-303-clld42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
R (max)	4.8 mOhm
Insert configuration value	0B.303 - 3 Low Voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	8 A
Vtest (contact-contact)	1200 V (AC), 1700 V (DC)
Vtest (contact-shell)	900 V (AC), 1270 V (DC)
Contact Type	Solder
Max. Solid Conductor	0.56 mm ² (AWG 20)
Max. Stranded Conductor	0.56 mm ² (AWG 20)
Bucket Dia.	1.0 mm (0.039in)
Contact Dia.	0.9 mm (0.035in)
Number of contacts Low Voltage	3
Wire Size/AWG	28 - 20
Gender	Reverse Gender

Form & Material

Shell style / Model id	FS - Adjustable right angle Anglissimo plug (8 selective positions) with cable collet
Plug	Elbow
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	2 keys (gamma=45, plug: female contacts, receptacle: male contacts)
Colour	Grey
Weight	11.24 g

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsj-0b-303-clld42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Note	Cable diameter is specific for Anglissimo to enable easy termination of connector
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	3.30 - 4.20 mm

Drawings

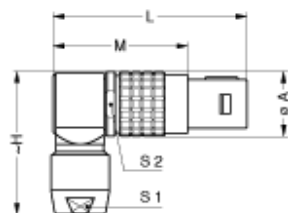

Dimensions

	A	H	L	M	S1	S2
mm.	10	22.4	30.3	20.2	7	9
in.	0.39	0.88	1.19	0.8	0.28	0.35

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fsj-0b-303-clld42.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories		
Tools		
Spanner		DCP.91.001.TN
Spanner 2		DCP.91.FSG.TN
Spanner wrench		DCD.0B.ZZZ.PA070

Cables

Cable PartNumber	Material	Colour	Cable image
30110	PVC	Grey	
3280	PVC	Black	