


PXMBNI08FBF03ASC Datasheet

Product Name // M8 Series A Code Brass Nickel Plated
PG7 Flex Body 3 Contact Socket

 [View Product Page](#)

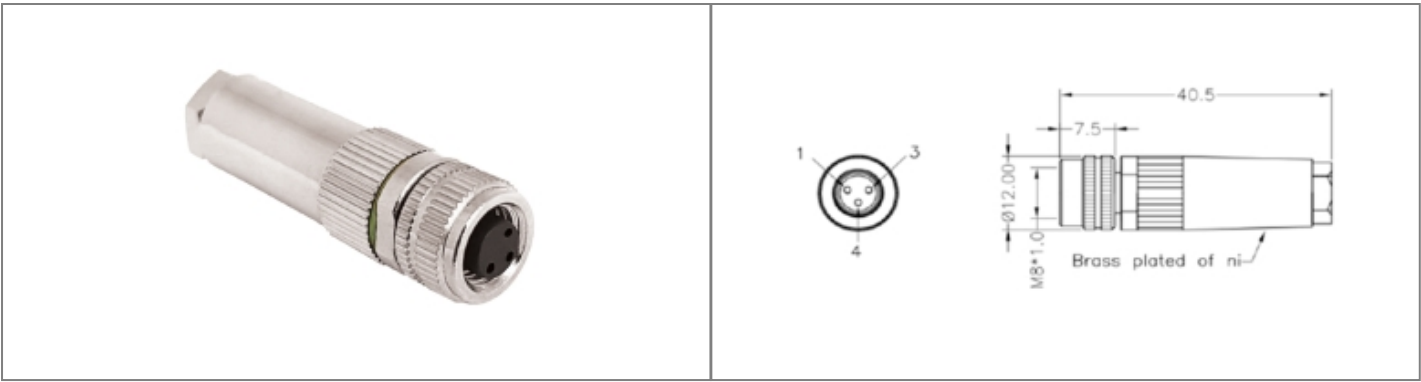

// Product Description:	
 M8 Series Brass Nickel Plated Flex Body Connectors	 3, 4, 5 Contact (3, 4 Contact are A Code, 5 Contact are B Code)
 Water and dustproof to IP67 when mated with compatible connector	 Solder Terminals
 Socket only	 Mate with M8 Series Inline Body and Panel Mount Connectors

// General Information:	
Product Display Title:	M8 Series Brass Nickel Plated Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Approvals:	CSA, UL, RCM
Body Material:	Brass - Nickel Plated
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	3A
Diameter Over Coupling Ring Mm:	12.5mm
Function:	Flex Cable Connector Body
Ip Rating:	IP67
M12 Series Mounting Nut:	PG7
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	3 Contacts
Pin Layout Code:	A Code
Thread Size:	M8 x 1
Voltage Max:	60V

// Product PDF Links

 M8 Series automation connectors...

// Product 3D CAD Model Links

 PXMBNI08FBF03ASC3D CAD Model