

All AMP MCP, SEALED CONNECTOR HOUSING (130)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

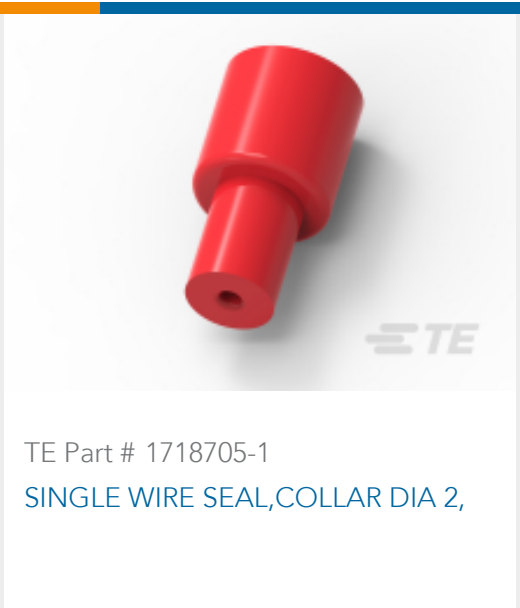
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

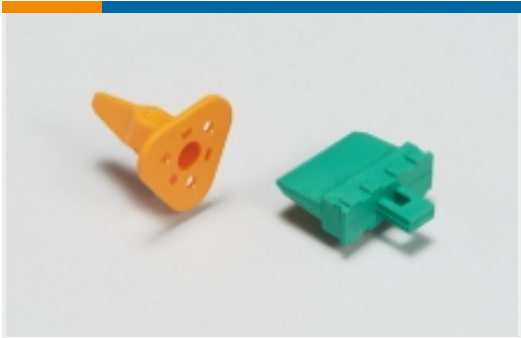
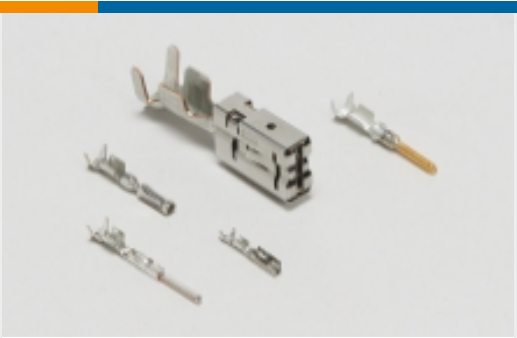
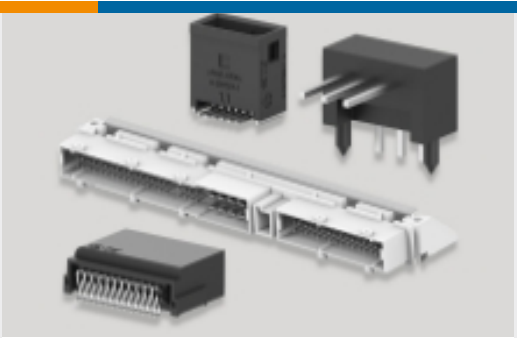
This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



 TE Part # 963531-1 BLINDSTOPFEN	 TE Part # 963530-1 EINZELLEITERDICHTNG	 TE Part # 1718705-1 SINGLE WIRE SEAL, COLLAR DIA 2,	 TE Part # 964972-1 EINZELLEITERDICHTNG
 TE Part # 964971-1 EINZELLEITERDICHTNG	 TE Part # CAT-AM705-T273 AMP MCP, RECEPTACLE AND TAB	 TE Part # 1897210-1 MCP HYB 4P PLUG ASSY	

Also in the Series | AMP MCP Connector System

 Automotive Connector Caps & Covers (24)	 Automotive Connector Locks & Position Assurance(4)	 Automotive Housings(260)	 Automotive Terminals(11)
 Connector Seals & Cavity Plugs(5)	 Insertion & Extraction Tools(13)	 Other Automotive Connector Accessories(2)	 PCB Headers & Receptacles(28)

Also in the Series | AMP MCP Hybrids



Automotive Connector Caps & Covers
(4)



Automotive Housings(49)

Customers Also Bought



TE Part #1355348-1
MQS, CONNECTOR HOUSING



TE Part #1-1718485-1
CARRIER FOR RECEPT. INSERTS 36
POS



TE Part #1801600-1
RECEPTACLE HOUSING, MCON, 10
W, SEALED



TE Part #3-1718324-1
1.5/2.8MM TAB HSG.,62POS.,ASSY



TE Part #776488-1
AMPSEAL 16 Housings



TE Part #2-967630-1
FLA-STE-GEH2,8MM21P



TE Part #1-962919-1
TIMER, RECEPTACLE AND TAB

Documents

Product Drawings
MCP HYB 4P CAP HSG

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1897209-2_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1897209-2_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1897209-2_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.



Product Specifications

MCP HYB 4P

English