

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257

<https://www.phoenixcontact.com/us/products/1419257>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing D7, for single locking latch, material: PA, cable outlets: 1, lateral, M20, height: 54.5 mm, cable gland: with, Standard

## Commercial data

Item number	1419257
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	BF7APD
Catalog page	Page 514 (C-2-2019)
GTIN	4055626159980
Weight per piece (including packing)	26.417 g
Weight per piece (excluding packing)	26.417 g
Customs tariff number	85389099
Country of origin	CN

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257

<https://www.phoenixcontact.com/us/products/1419257>

## Technical data

### Notes

General	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
---------	---


### Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Product family	HC-STA-D07
Application	Standard
Type	D7
No. of cable outlets	1
Type of the screw connection	M20
Shielded	no
Cable outlet	lateral
Pg screw connection	with

### Data management status

Article revision	01
------------------	----

### Dimensions

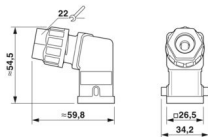Dimensional drawing	
Width	26.5 mm
Height	54.5 mm
Length	26.5 mm

### Material specifications

Flammability rating according to UL 94	V0 (Housing)
Housing material	PA
Locking latch material	PA

### Mechanical properties

#### Mechanical data

Type of the screw connection	M20
Locking type	Pin

### Cable/line

External cable diameter Cable 1	4 mm ... 10 mm
---------------------------------	----------------

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257

<https://www.phoenixcontact.com/us/products/1419257>

## Connection data

External cable diameter	4 mm ... 10 mm
-------------------------	----------------

## Environmental and real-life conditions

### Ambient conditions

Degree of protection	IP66
Impact strength	IK06
Ambient temperature (operation)	-40 °C ... 125 °C

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing


1419257

<https://www.phoenixcontact.com/us/products/1419257>



## Drawings

Dimensional drawing

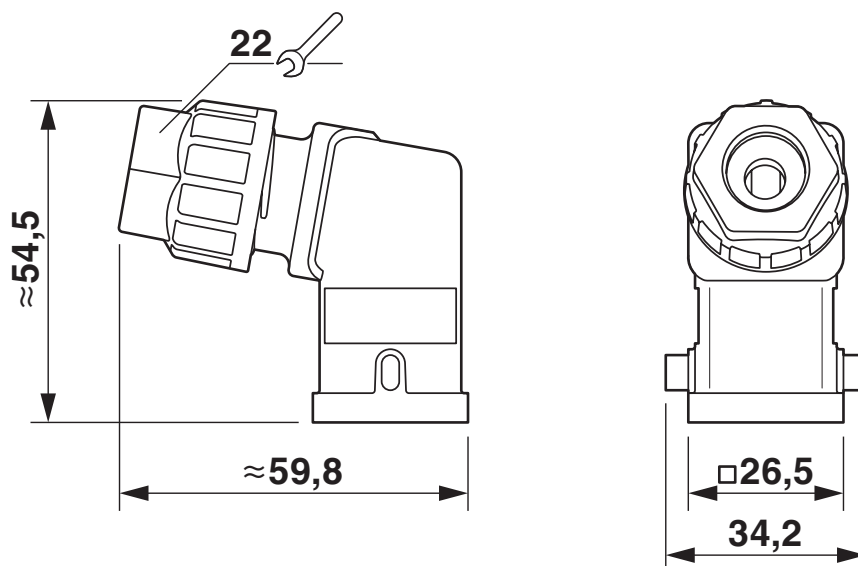

Dimensional drawing

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257

<https://www.phoenixcontact.com/us/products/1419257>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1419257>

### DNV

Approval ID: TAE000037S



### EAC

Approval ID: RU C-DE.BL08.B.00511

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257

<https://www.phoenixcontact.com/us/products/1419257>

## Classifications

### ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

### ETIM

ETIM 9.0	EC000437
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# HC-STA-D07-HHFS-1SGM20-PL-BK - Housing



1419257  
<https://www.phoenixcontact.com/us/products/1419257>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)