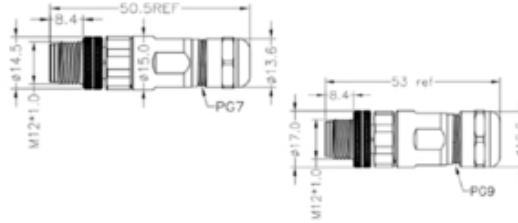


**Product Name // M12 Series A Code Brass Nickel Plated PG7 Inline Body 4 Contact Pins**
[View Product Page](#)

**// Product Description:**

- ◊ M12 Series Brass Nickel Plated Inline Body Connectors
- ◊ Water and dustproof to IP67 when mated with compatible connector
- ◊ Pin only
- ◊ 3, 4, 5, 8, 12 Contact (3, 8, 12 Contact are A Code, 4 Contact are choice of A Code A or D Code, 5 Contact are choice of A Code or B Code)
- ◊ Solder Terminals
- ◊ Choice of gland nut sizes, depending on part code
- ◊ Choice of Sealing Caps available separately to maintain IP rating of unmated connectors
- ◊ Mate with M12 Series Flex Body and Panel Mount Connectors

**// General Information:**

Product Display Title:	M12 Series Brass Nickel Plated Inline Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Approvals:	CSA, ENEC, UL, VDE
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	4A
Diameter Over Coupling Ring Mm:	20mm
Function:	Inline Cable Connector Body
Ip Rating:	IP67
M12 Series Mounting Nut:	PG7
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	4 Contacts
Pin Layout Code:	A Code
Thread Size:	M12 x 1
Voltage Max:	250V

**// Product PDF Links**
[M12 Series automation connectors...](#)
**// Product 3D CAD Model Links**
[PXMBNI12FIM04ASCPG73D CAD Model](#)

 Have a question or project enquiry  
 you'd like to talk to us about?

[Click Here To Contact Us](#)