

Image for illustrative purpose only

Summary

Request a quote	
Catalog	
Number of contacts Low Voltage	10
Wire Size/AWG	20 - 18
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Jacket cable outside diameter [mm]	7.60 - 8.00 mm
Size	3K
Suggested matching part	EGG.3K.310.CYM
Series	K - Outdoor keyed

Technical details

Electrical Configuration

Contact Termination Low voltage	Crimp
R (max)	3.6 mOhm
Insert configuration value	3K.310 - 10 Low Voltage
Insulator	Y: PEEK for crimp contacts
Rated current	12 A
Vtest (contact-contact)	1500 V (AC), 2150 V (DC)
Vtest (contact-shell)	1800 V (AC), 2550 V (DC)
Contact retention	40 N
Contact Type	Crimp
Max. Conductor	1 mm ² (AWG 18)
Min. Conductor	0.5 mm ² (AWG 20)
Bucket Dia.	1.4 mm (0.055in)
Contact Dia.	1.3 mm (0.051in)
Number of contacts Low Voltage	10
Wire Size/AWG	20 - 18
Gender	Standard

Form & Material

Shell style / Model id	FG - Straight plug, cable collet
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell, collet nut and latch sleeve, nickel plated [SAE AMS QQ N 290] brass mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-310-cycc80.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Test and Measurement
Environmental sealing (IP rating)	IP68
Endurance	5000 mating cycles
Temperature range	-55°C / +200°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	95 dB (10 MHz)
Shielding (min)	80 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	7.60 - 8.00 mm

Drawings

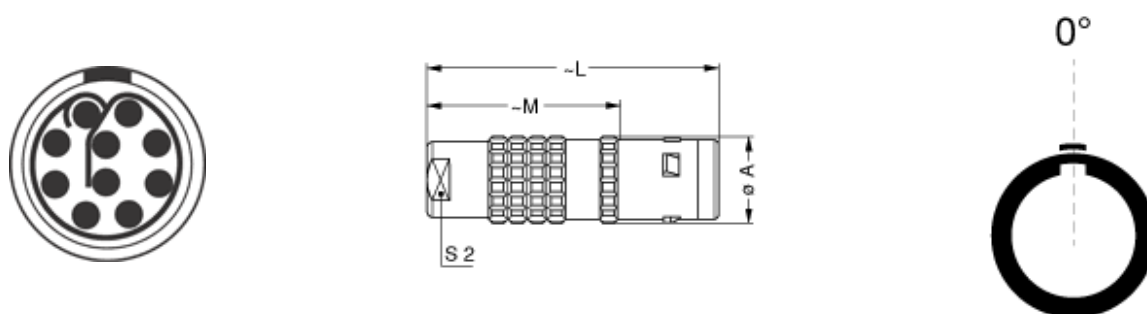

Dimensions

	A	L	S2	M
mm.	19	61	15	41
in.	0.75	2.4	0.59	1.61

https://www.lemo.com/int_en/solutions/originals/k-outdoor-keyed/fgg-3k-310-cycc80.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo

Accessories	
Replacement contact	FGG.3B.565.ZZC
Compatible cap	BFG.3K.100.NAS
Tools	
Positionner	DCE.91.133.BVC
Extraction tool	DCC.13.15B.LAG
Crimp tool	DPC.91.701.V
Spanner wrench	DCD.3E.ZZZ.PA150

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.10.T20.080PGZE		grey	
CMN.10.T20.080PNZE			
CMN.10.T20.080QGC	TPR	Grey	