

*Image for illustrative purpose only*

Summary

[Request a quote](#)[Catalog](#)

Nb of contacts Coax	2
Wire Size/AWG	30 - 22
Gender	Standard
Plug	Plug - Straight
Locking system	Push-pull
Size	3B
Suggested matching part	EEG.3B.846.CLL1
Series	B - Indoor keyed

Technical details

Electrical Configuration

Nb of contacts Coax	2
Contact Termination Coax	Crimp
R (max)	5.8 mOhm
Insert configuration value	3B.846 - 2 Coax (50 Ohm), 6 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated current	10 A
Test voltage (kV DC)	1.3
Contact Type	Coaxial 50 Ohm (Crimp) Type C
Contact Dia.	0.7 mm (0.03in)
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	FG - Straight plug, cable adapter and nut for fitting a bend relief
Plug	Straight
Housing material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Locking system	Push-pull
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Colour	Grey
Variant	Nut for fitting a bend relief
Weight	49.41 g

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgg-3b-846-clad71z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.




Environment

Technical domain	Audio Video, Energy and Industrial, Medical, Semiconductor, Specialties and Other, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	5000 mating cycles
Temperature range	-55°C / +250°C
Climatical Category	50/175/21
Humidity (max)	<=95% [at 60 deg C /140 F]
Shielding (min)	75 dB (10 MHz)
Shielding (min)	40 dB (1 GHz)
Shock Resistance	100 g [6 ms]
Vibration	15 g [10 Hz - 2000 Hz]
Salt Spray Corrosion	>1000 hr

Cable fixation

Cable termination protection	For cable bend relief
Fixation type	Cable collet

Drawings

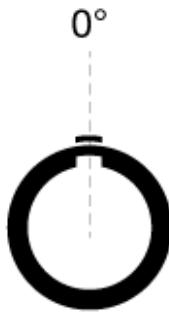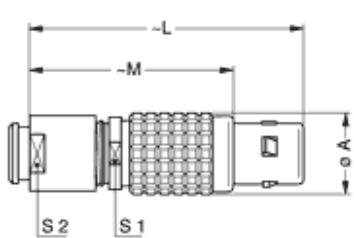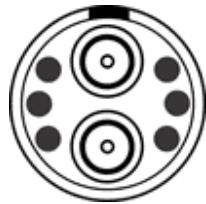

Dimensions

	S1	M	L	S2	A
mm.	15	41.5	56.5	15	18
in.	0.59	1.63	2.22	0.59	0.71

https://www.lemo.com/int_en/solutions/originals/b-indoor-keyed/fgg-3b-846-clad71z.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.