


VS-04-BUA-FK-F/IP67 - USB female insert



1653854

<https://www.phoenixcontact.com/us/products/1653854>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

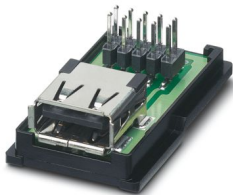

USB socket insert, 4-pos., socket USB type A on flat-ribbon cable terminal strip, pitch 2.54, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

Commercial data

Item number	1653854
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AB14
Product key	ABNNFC
Catalog page	Page 453 (C-2-2019)
GTIN	4017918970185
Weight per piece (including packing)	13.5 g
Weight per piece (excluding packing)	13.5 g
Customs tariff number	85366990
Country of origin	DE

VS-04-BUA-FK-F/IP67 - USB female insert



1653854

<https://www.phoenixcontact.com/us/products/1653854>

Technical data

Product properties

Product type	Female insert
Type	USB-A
Number of positions	4
Connection profile	USB
Number of slots	1
Type	Socket
Shielded	no

Data management status

Article revision	08
------------------	----

Electrical properties

Rated voltage (III/3)	30 V
Rated current	1 A
Insulation resistance	$\geq 1 \text{ G}\Omega$
Transmission medium	Copper
Transmission characteristics (category)	USB 2.0

Connection data

Connection technology

Connection method	Flat-ribbon cable connection
-------------------	------------------------------

Dimensions

Width	22.8 mm
Height	16.5 mm
Length	38.1 mm

Material specifications

Flammability rating according to UL 94	V0
Housing material	Plastic
Contact material	Copper alloy
Contact surface material	Gold
Contact carrier material	PET

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 1000
-----------------------------	-------------

Environmental and real-life conditions

Ambient conditions

VS-04-BUA-FK-F/IP67 - USB female insert



1653854

<https://www.phoenixcontact.com/us/products/1653854>

Degree of protection	IP20
Ambient temperature (operation)	-15 °C ... 65 °C


VS-04-BUA-FK-F/IP67 - USB female insert



1653854
<https://www.phoenixcontact.com/us/products/1653854>

Drawings

Schematic diagram

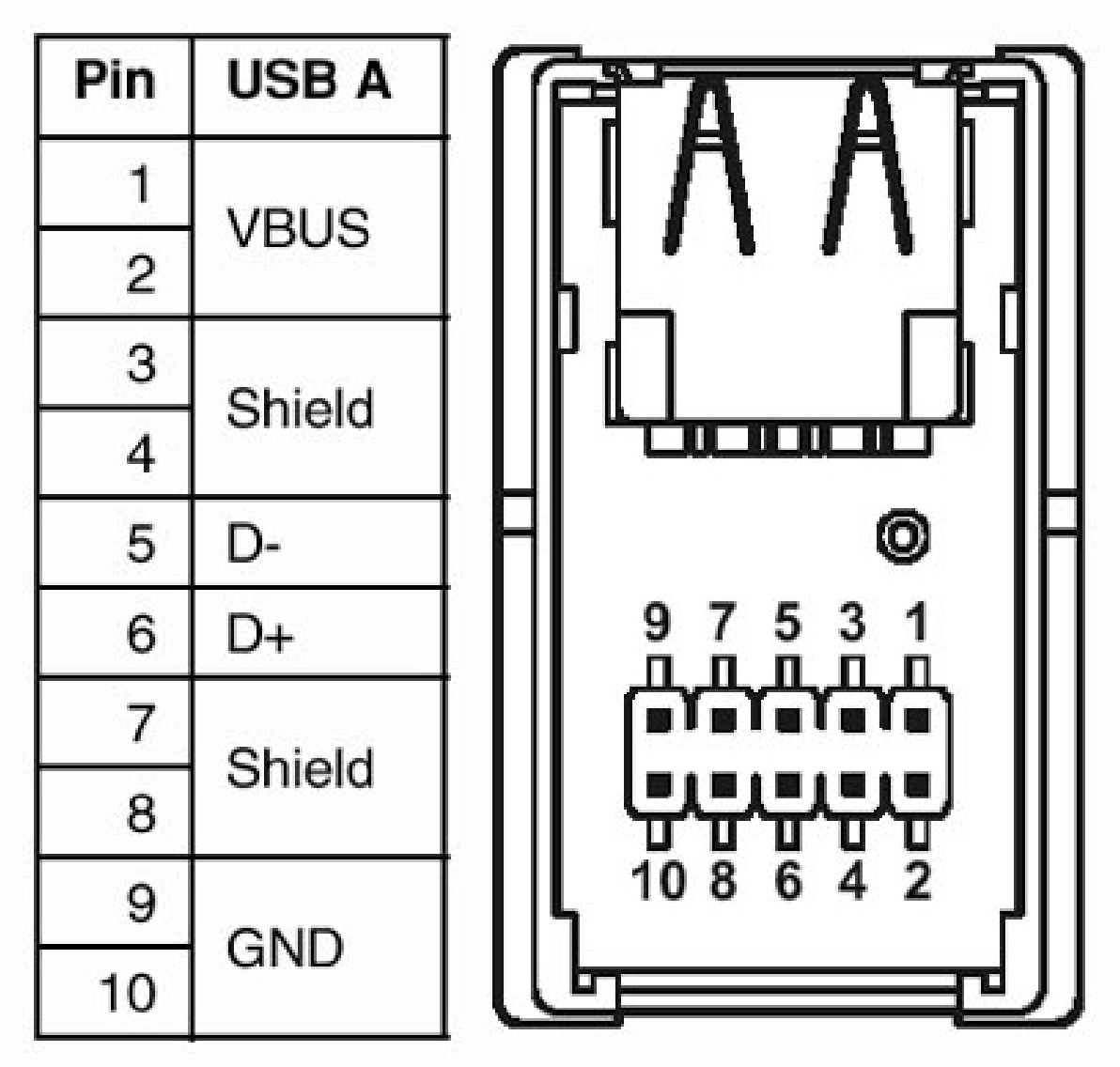

Contact assignment


VS-04-BUA-FK-F/IP67 - USB female insert

1653854

<https://www.phoenixcontact.com/us/products/1653854>



Schematic diagram

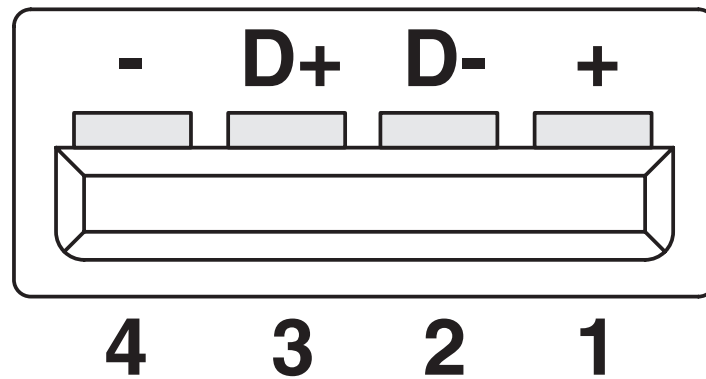

Pin assignment socket USB, type A

VS-04-BUA-FK-F/IP67 - USB female insert



1653854

<https://www.phoenixcontact.com/us/products/1653854>

Classifications

ECLASS

ECLASS-11.0	27440223
ECLASS-12.0	27440223
ECLASS-13.0	27440223

ETIM

ETIM 9.0	EC003557
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

VS-04-BUA-FK-F/IP67 - USB female insert



1653854

<https://www.phoenixcontact.com/us/products/1653854>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com