

Basic features

Approval/Conformity	CE cURus WEEE
---------------------	---------------------

Environmental conditions

Ambient temperature	-25...85 °C
IP rating	IP67

Electrical connection

Cable diameter D	10...12 mm
Connection	7/8"-16 UN-Female, straight, 3-pin
Number of connectable contacts	3
System	Can be fabricated

Material

Material contact carrier	PUR, PA
Material contacts	Brass
Material cover nut	Die-cast zinc
Material grip	PBT

Electrical data

Operating voltage Ub	600 VDC / 600 VAC
Rated current (40 °C)	9.0 A


Mechanical data

Connection cross-section	0.14...1.5 mm ²
Tightening torque pigtail	1.5 Nm
Type of wire mounting	Screw terminals

Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

Connector Drawings

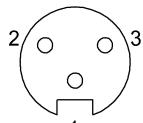

PIN 1-3 usable