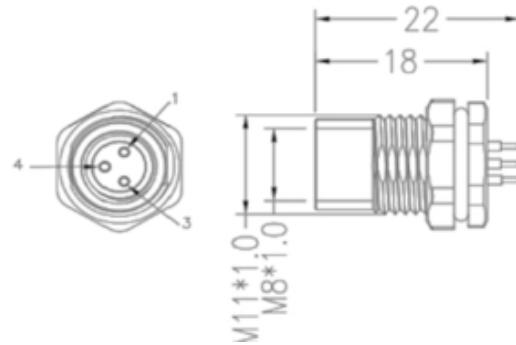


**Product Name // PXMBNI08RPM08AFLM8002**
[View Product Page](#)

**// Product Description:**

- Material=Metal
- Pins=4
- Max Rating=30Vac
- Ingress Protection=IP67
- Operating Temperature= -25°C to +85°C
- Contact Resistance=5?
- Insulation Resistance=>100M?
- Mechanical Cycles=100 (min)

**// General Information:**

Product Display Title:	M8 Series Rear Panel Mount Connectors
Product Family:	Circular Automation Connectors
Product Series:	M8 Series
Body Material:	Brass - Nickel Plated
Contact Type:	Plug Contact
Number Of Contacts:	8 Contacts

**// Product PDF Links**
 M8 Series automation connectors...

**// Product 3D CAD Model Links**
 PXMBNI08RPM08AFLM80023D CAD Model

 Have a question or project enquiry  
 you'd like to talk to us about?

 [Click Here To Contact Us](#)