

# SAC-4PY-MT/2XFT VP - Y distributor



1410632

<https://www.phoenixcontact.com/us/products/1410632>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Y distributor, 4-position, Plug straight M12, coding: T, on Socket straight M12, coding: T and Socket straight M12, coding: T, For direct current up to 12 A/63 V

## Your advantages

- High-performance: DC connectors for up to 12 A and 63 V DC

## Commercial data

Item number	1410632
Packing unit	5 pc
Minimum order quantity	1 pc
Sales key	BF10
Product key	BF1GAP
Catalog page	Page 184 (C-6-2019)
GTIN	4046356924726
Weight per piece (including packing)	38.36 g
Weight per piece (excluding packing)	38.36 g
Customs tariff number	85366990
Country of origin	PL

# SAC-4PY-MT/2XFT VP - Y distributor



1410632

<https://www.phoenixcontact.com/us/products/1410632>

## Technical data

### Product properties

Product type	Y-distributor
Application	Power supply
Number of positions	4
No. of cable outlets	2
Shielded	no
Coding	T
Thread type	M12

### Insulation characteristics

Overvoltage category	III
Degree of pollution	3


### Electrical properties

Insulation resistance	$\geq 100\text{ M}\Omega$
Nominal voltage $U_N$	63 V DC
Nominal current $I_N$	2x 12 A (at 40 °C)

### Signaling

Status display	no
Status display present	No

### Dimensions

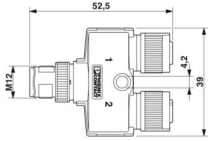Dimensional drawing	
Length	52.5 mm
Center distance	21 mm

### Material specifications

Flammability rating according to UL 94	HB
Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	PA
Material for screw connection	Zinc die-cast, nickel-plated

### Connector

Connection 1
--------------

# SAC-4PY-MT/2XFT VP - Y distributor



1410632

<https://www.phoenixcontact.com/us/products/1410632>

Type	Plug straight M12
Coding type	T

## Connection 2

Type	Socket straight M12
Coding type	T

## Connection 3

Type	Socket straight M12
Coding type	T

## Mechanical properties

### Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	-------

## Environmental and real-life conditions

### Ambient conditions

Degree of protection	IP65
	IP67
Ambient temperature (operation)	-25 °C ... 85 °C (Plug / socket)

## Standards and regulations

Standard designation	M12 connector
Standards/specifications	IEC 61076-2-111

# SAC-4PY-MT/2XFT VP - Y distributor


1410632

<https://www.phoenixcontact.com/us/products/1410632>




## Drawings

Schematic diagram

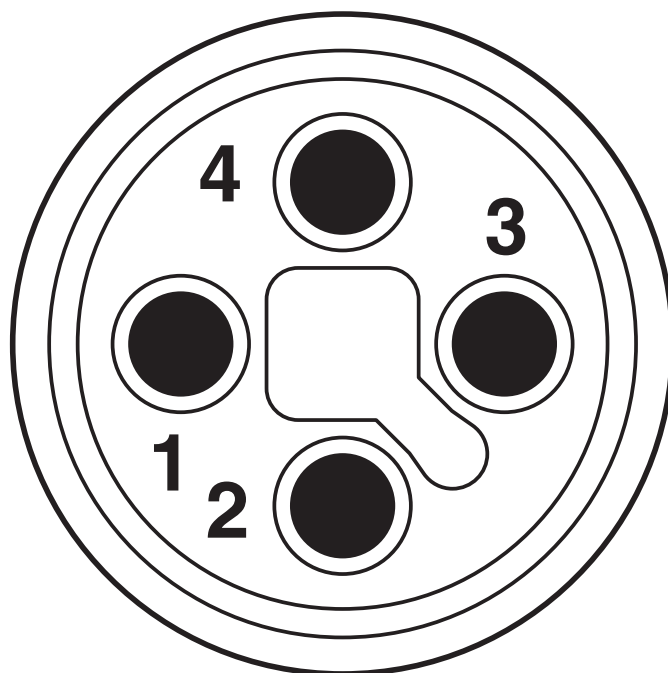

Pin assignment for M12 plug, 4-pos., T-coded, view of plug side

Diagram

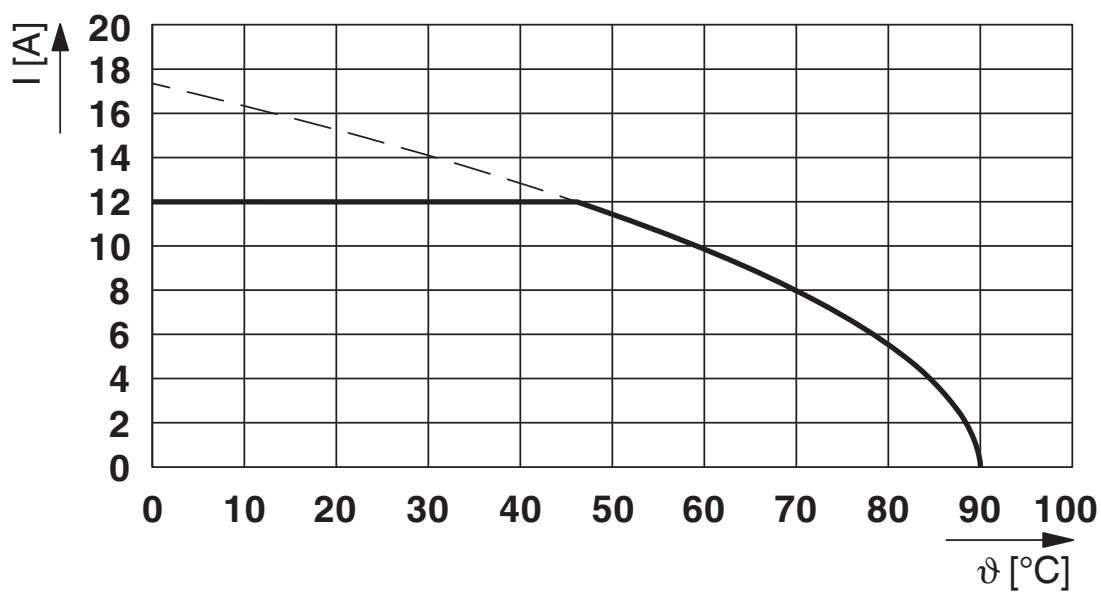

Current carrying capacity


# SAC-4PY-MT/2XFT VP - Y distributor

1410632

<https://www.phoenixcontact.com/us/products/1410632>




Dimensional drawing

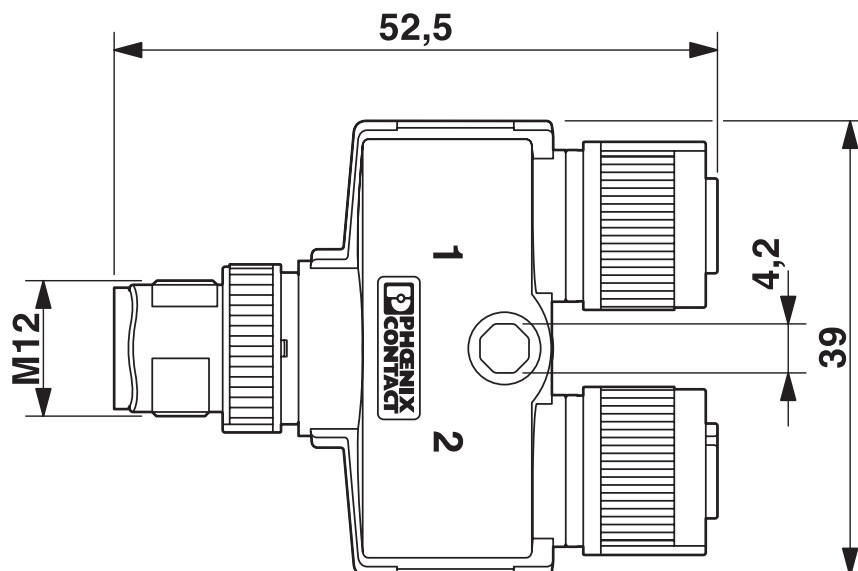

M12 Y distributor

Circuit diagram

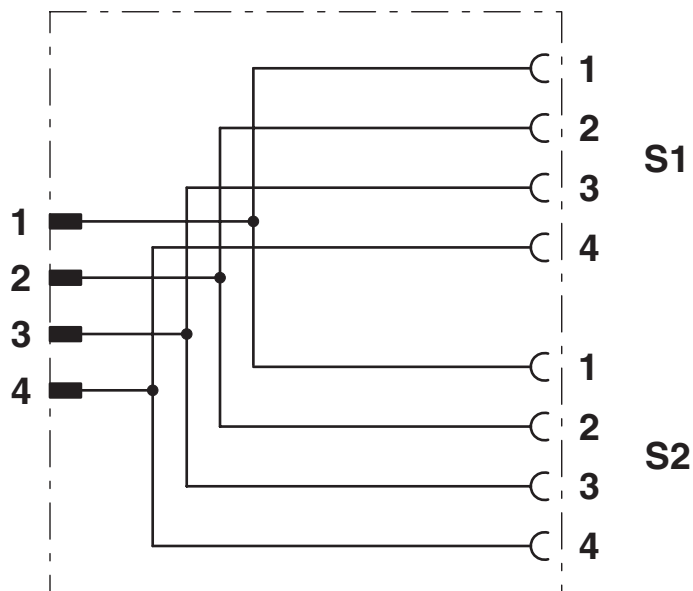


# SAC-4PY-MT/2XFT VP - Y distributor

1410632

<https://www.phoenixcontact.com/us/products/1410632>



Schematic diagram

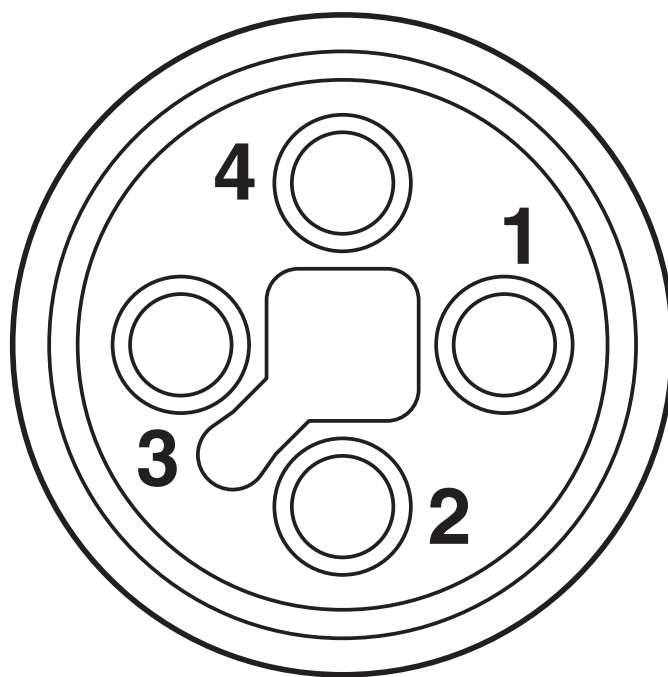

Pin assignment of M12 socket, 4-pos., T-coded, socket side view

# SAC-4PY-MT/2XFT VP - Y distributor



1410632

<https://www.phoenixcontact.com/us/products/1410632>

## Classifications

### ECLASS

ECLASS-11.0	27440106
ECLASS-12.0	27440106
ECLASS-13.0	27440106

### ETIM

ETIM 9.0	EC002925
----------	----------

### UNSPSC

UNSPSC 21.0	31251500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	cbdc3b3c-ca1c-4572-9f02-5926c272a288



# SAC-4PY-MT/2XFT VP - Y distributor



1410632

<https://www.phoenixcontact.com/us/products/1410632>

## Accessories

### PROT-M12 - Screw plug

1680539

<https://www.phoenixcontact.com/us/products/1680539>



An M12 screw plug for the unoccupied M12 sockets of the sensor/actuator cable, boxes and flush-type connectors

---

### PROT-M12 FS - Sealing cap

1560251

<https://www.phoenixcontact.com/us/products/1560251>



M12 sealing cap for unoccupied M12 plugs of the sensor/actuator cable, flush-type plugs and I/O devices in the field

# SAC-4PY-MT/2XFT VP - Y distributor

1410632

<https://www.phoenixcontact.com/us/products/1410632>



## PROT-M12 MS-PA-CHAIN - Screw plug

1430899

<https://www.phoenixcontact.com/us/products/1430899>

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



---

## PROT-M12 FS-PA-CHAIN - Sealing cap

1430873

<https://www.phoenixcontact.com/us/products/1430873>

M12 sealing cap made of plastic with fixing band, for sensor cables, for free M12 plugs



# SAC-4PY-MT/2XFT VP - Y distributor

1410632

<https://www.phoenixcontact.com/us/products/1410632>



## TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/us/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

---

## SAC BIT M12-D15 - Tool

1208432

<https://www.phoenixcontact.com/us/products/1208432>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a knurl diameter of 15 mm, for 4 mm hexagonal drive

---

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)