

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2119661002

Status:


Active

Overview:

[SlimSAS Connectors and Cable Assemblies](#)

Description:

SlimSAS Receptacle, Vertical, 8x (74 Circuits), 85 Ohm, 0.75um Gold (Au) Plating, 2.20mm Shell Tab Length, Black

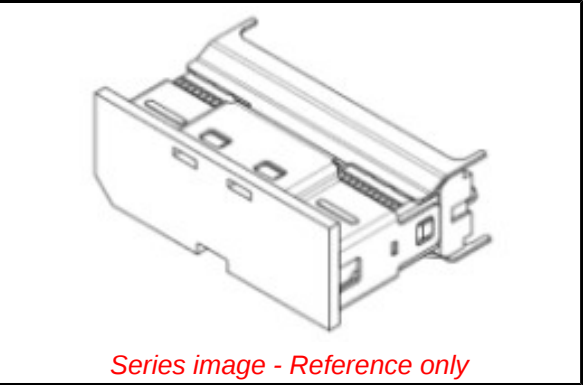

Documents:

[Drawing \(PDF\)](#)

[Product Specification 2119661000-000 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	I/O Connectors
Series	211966
Application	Wire-to-Board
Component Type	Receptacle
Overview	SlimSAS Connectors and Cable Assemblies
Product Name	SlimSAS
Type	N/A
UPC	193264238538
Physical	
Circuits (Loaded)	74
Circuits (maximum)	74
Color - Resin	Black
Durability (mating cycles max)	250
Gender	Female
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Matte Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	2.288/g
Number of Rows	2
Orientation	Vertical
PCB Locator	Yes
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	0.60mm
Pitch - Termination Interface	0.60mm
Plating min - Mating	0.750µm
Polarized to Mating Part	Yes
Polarized to PCB	No
Ports	1
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC
Material Info	
Reference - Drawing Numbers	
Product Specification	2119661000-000
Sales Drawing	2119661001-000

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

211966 Series

This document was generated on 09/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION