

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B24, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, 1x Pg21, height: 60 mm, cable gland: none, Standard

## Your advantages

- Good shielding in the event of electromagnetic interference

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1412791             |
| Packing unit                         | 1 pc                |
| Minimum order quantity               | 1 pc                |
| Sales key                            | BF56                |
| Product key                          | BF7APB              |
| Catalog page                         | Page 634 (C-2-2019) |
| GTIN                                 | 4055626060576       |
| Weight per piece (including packing) | 244.7 g             |
| Weight per piece (excluding packing) | 240.2 g             |
| Customs tariff number                | 85389099            |
| Country of origin                    | CN                  |

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

## Technical data

### Notes

|         |                                                                                           |
|---------|-------------------------------------------------------------------------------------------|
| General | for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M                                  |
| General | also available as a powder-coated or color version: 1373268 HC-STA-B24-HLFS-1TTP21-EL/... |

 
### Product properties

|                              |                            |
|------------------------------|----------------------------|
| Product type                 | Housing with locking latch |
| Housing type                 | Sleeve housing             |
| Application                  | Standard                   |
| Type                         | B24                        |
| No. of cable outlets         | 1                          |
| Type of the screw connection | 1x Pg21                    |
| Type                         | Low design                 |
| Cable outlet                 | straight                   |
| Pg screw connection          | none                       |

### Data management status

|                  |    |
|------------------|----|
| Article revision | 03 |
|------------------|----|

### Dimensions

|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 44 mm                                                                                |
| Height              | 60 mm                                                                                |
| Length              | 120 mm                                                                               |

### Material specifications

|                          |                                         |
|--------------------------|-----------------------------------------|
| Housing material         | Die-cast aluminum, salt water resistant |
| Housing surface material | uncoated                                |

### Mechanical properties

#### Mechanical data

|                              |         |
|------------------------------|---------|
| Type of the screw connection | 1x Pg21 |
| Locking type                 | Pin     |

### Environmental and real-life conditions

#### Ambient conditions

|                      |      |
|----------------------|------|
| Degree of protection | IP66 |
|----------------------|------|

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

|                                 |                   |
|---------------------------------|-------------------|
|                                 | IP67              |
| Enclosure rating (NEMA)         | 4 (UL 50e)        |
|                                 | 4X (UL 50e)       |
|                                 | 12 (UL 50e)       |
| Impact strength                 | IK08              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing


1412791

<https://www.phoenixcontact.com/us/products/1412791>



## Drawings

Dimensional drawing

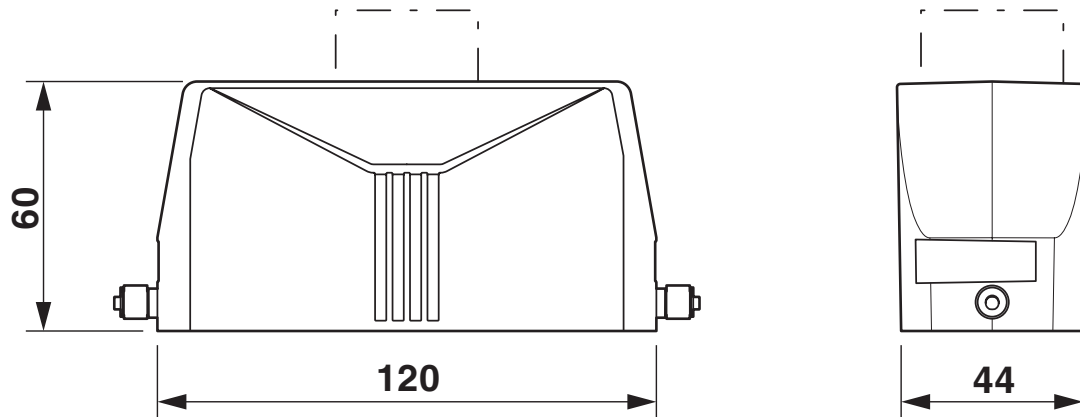

Dimensional drawing

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1412791>

**DNV**

Approval ID: TAE000037S



**cUL Recognized**

Approval ID: E255026



**UL Recognized**

Approval ID: E255026



**EAC**

Approval ID: RU C-DE.AI30.B.01102



**EAC**

Approval ID: RU C-DE.BL08.B.00511

**cULus Recognized**

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27440202 |
| ECLASS-12.0 | 27440202 |
| ECLASS-13.0 | 27440202 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000437 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-STA-B24-HLFS-1TTP21-EL-AL - Housing



1412791

<https://www.phoenixcontact.com/us/products/1412791>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2024 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)