



Image for illustrative purpose only

Summary

[Request a quote](#)

[Catalog](#)

Number of contacts Low Voltage	12
Wire Size/AWG	30 - 22
Gender	Standard
Socket / Receptacle	Socket / Receptacle - Fixed Panel Rear Mounted
Locking system	Push-pull
Jacket cable outside diameter [mm]	1.00 - 15.60 mm
Size	2P
Suggested matching part	CAB.M12.GLA.C72GZ
Series	REDEL P - Push-Pull

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m12-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Technical details

Electrical Configuration

Contact Termination Low voltage	Solder
Insert configuration value	2P.M12 - 12 Low V.
Insulator	L: PEEK for solder contacts
Rated current	7 A
Test voltage (kV rms) Contact-contact	1.25
Contact Type	Solder
Air clearance	0.85 mm
Creepage distance	0.85 mm
Bucket Dia.	0.8 mm (0.031in)
Contact Dia.	0.7 mm (0.027in)
Number of contacts Low Voltage	12
Wire Size/AWG	30 - 22
Gender	Standard

Form & Material

Shell style / Model id	CK - Fixed receptacle with two nuts (back panel mounting)
Socket / Receptacle	Fixed Panel Rear Mounted
Housing material	PSU (Polysulfone), gray
Locking system	Push-pull
Keying	3 keys (alpha=0, gamma=60, Plug: male contacts, Receptacle: female contacts)
Weight	5.66 g

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m12-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.


Environment

Technical domain	Energy and Industrial, Medical, Test and Measurement, Transportation, Aerospace and UAV
Environmental sealing (IP rating)	IP50
Endurance	>5000 mating cycles
Temperature range	-50°C / +150°C
F ret (max)	250 N
F ret (min)	150 N
Steam sterilization	Fully sterilizable (Steam, Gamma, ETO) following our protocols and tests in line with ISO 11134 and IEC 60601-1 standards. For more details on sterilization methods and cycles, please contact us.

Cable fixation

Cable termination protection	Standard back nut (no additional protection)
Fixation type	Cable collet
Jacket cable outside diameter [mm]	1.00 - 15.60 mm

Drawings

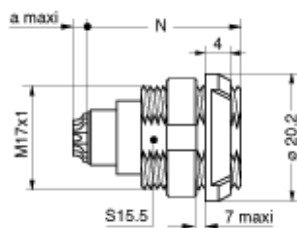

Dimensions

	N	a
mm.	23.8	3.4-4.9
in.	0.94	

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m12-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Recommended By Lemo






 
 
 

 

Accessories

Tools

Spanner

[COP.155.GN](#)

Cables

Cable PartNumber	Material	Colour	Cable image
CMN.12.T22.070QGZE	TPR (medical)	Grey	
CMN.12.T28.054PGZE		grey	
CMN.12.T28.054PNZE			
112240	PTFE	White	
112260	PTFE	White	
112280	PVC	Black	
12050	PVC	Black	
124080	PVC	Grey	
124084	PVC	Black	
212220	PVC	Black	
212240	PVC	Black	
212250	PVC	Grey	
212260	PVC	Black	

https://www.lemo.com/int_en/solutions/redel/redel-p-push-pull/ckb-m12-gllg.html

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.