



Connectors > Contacts > Connector Contacts



Contact Type: **Tab**
Contact Mating Area Plating Material: **Silver**
Wire Contact Termination Area Plating Material: **Silver**
Wire Size: **5 – 6 mm²**

Features

Contact Features

Mating Tab Width	5.84 mm[.23 in]
Mating Tab Thickness	2.67 mm[.105 in]
Wire Contact Termination Area Plating Thickness	2.54 µm[100 µin]
Wire Contact Termination Area Plating Material Finish	Bright
Contact Mating Area Plating Material Thickness	2.54 µm[100 µin]
Contact Orientation	Right Angle
Contact Underplating Material	Copper
Contact Type	Tab
Contact Mating Area Plating Material	Silver
Wire Contact Termination Area Plating Material	Silver
Contact Base Material	Copper
Contact Current Rating (Max)	35 A

Termination Features

Termination Method to Wire & Cable	Crimp
Product Terminates To	Wire & Cable

Mechanical Attachment

Wire Insulation Support	With
-------------------------	------

Dimensions

Compatible Insulation Diameter Range	4.83 – 5.59 mm[.19 – .22 in]
--------------------------------------	------------------------------



Wire Size	5 – 6 mm ²
-----------	-----------------------

Usage Conditions

Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]
-----------------------------	---------------------------

Operation/Application

Circuit Application	Power
---------------------	-------

Packaging Features

Packaging Quantity	1500
Packaging Method	Reel

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 206037-2
CPC PLUG ASSEMBLY SIZE 17-3



TE Part # 90384-1
HHHT TYPE XII MALE FEMALE 10 ASSY



TE Part # 7-1579008-6
UNLOCKING TOOL




TE Part # 1-66741-9
TYPE XII FEMALE CONT (STRIP)



TE Part # 2151411-2
OCEAN-2.0-APPLICATOR-S-210F220O-RSA



TE Part # 66741-9
TYPE XII FEMALE CONT (STRIP)

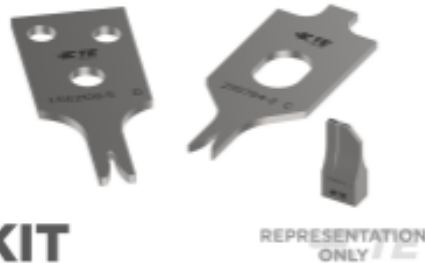

TE Part # 7-2151411-7
OCEAN_2.0_SPARE_PART_KIT-210F220O



TE Part # 567021-3
HDMIBMSMPR210F220OK 66251

Customers Also Bought



TE Part #206036-2
CPC SERIES 3



TE Part #208483-1
CMC RECEPTACLE ASSY,SIZE 28



TE Part #66740-9
TYPE XII FEMALE CONT (STRIP)



TE Part #211769-2
17-9 CPC RECEPT REV SEX



TE Part #5-104439-5
4X6 MTE RCPT SR PLAIN .100CL




TE Part #1-66358-7
III+ SKT,18-14,TIN ,STRIP



TE Part #211839-1
CPC RCPT SZ 23-24 W/THRD INSRT



TE Part #66741-9
TYPE XII FEMALE CONT (STRIP)

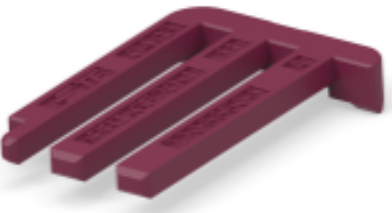

TE Part #2208850-1
RETAINER, FOR MCON1.2 CB

Documents



Product Drawings

MALE CONTACT ASSY. (STRIP)

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_66253-8_AF_c-66253-8-af.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_66253-8_AF_c-66253-8-af.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_66253-8_AF_c-66253-8-af.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMP Circular Connectors for Commercial Signal & Power Applications

English

Power Contacts

English

M_SERIES_PIN_AND_SOCKET_CONNECTORS

English

Product Specifications

Application Specification

English