

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Contact carrier, 4-position, Socket, straight, M12, coding: D, PCB mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239062

Your advantages

- Reduced mounting costs thanks to two-piece device connector
- Packaging available for automated pick and place assembly
- All common pin assignments and codings available
- Easy device integration thanks to mechanical port screw connections with threaded attachment, press-in contour or direct integration in the front plate
- Additional gasket for the device when not plugged in

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1414071 |
| Packing unit | 60 pc |
| Minimum order quantity | 60 pc |
| Sales key | AB23 |
| Product key | ABQAGS |
| GTIN | 4055626063898 |
| Weight per piece (including packing) | 4.572 g |
| Weight per piece (excluding packing) | 3.6 g |
| Customs tariff number | 85366930 |
| Country of origin | DE |

Technical data

Notes

| | |
|--------------------|--|
| Notes on operation | The electrical and mechanical data specified assume that the connector pair is correctly locked and mounted. If the connector is unlocked and if there is a danger of contamination, the connector must be sealed using a protective cap > IP54. Influences arising from litz wires, cables or PCB assembly must also be taken into consideration. |
|--------------------|--|

Product properties

| | |
|---------------------|----------------|
| Product type | Contact insert |
| Application | Data |
| Number of positions | Signal |
| Shielded | 4 |
| Coding | no |
| Thread type | D |
| | M12 |

Data management status

| | |
|------------------|----|
| Article revision | 03 |
|------------------|----|

Insulation characteristics

| | |
|----------------------|----|
| Overvoltage category | II |
| Degree of pollution | 3 |

Electrical properties

| | |
|-----------------------|----------------------------|
| Rated surge voltage | 2.5 kV |
| Contact resistance | $\leq 3 \text{ m}\Omega$ |
| Insulation resistance | $\geq 100 \text{ M}\Omega$ |
| Nominal voltage U_N | 250 V |
| Nominal current I_N | 4 A |

Connection data

| | |
|-------------------|-----------------------|
| Connection method | THR solder connection |
|-------------------|-----------------------|

Material specifications

| | |
|--|-------|
| Flammability rating according to UL 94 | V0 |
| Seal material | FKM |
| Contact material | CuZn |
| Contact surface material | Au |
| Contact carrier material | PA 6T |

Connector

| | |
|--------------|--------|
| Connection 1 | |
| Head design | Socket |

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



| | |
|-------------------|----------|
| Head cable outlet | straight |
| Head thread type | M12 |
| Coding | D |

Mechanical properties

Mechanical data

| | |
|-----------------------------|-------|
| Insertion/withdrawal cycles | > 100 |
|-----------------------------|-------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|--|
| Degree of protection | IP67 (correctly plugged in and locked) IP67 |
| Ambient temperature (operation) | -25 °C ... 85 °C (Plug / socket) -40 °C ... 85 °C (without mechanical actuation) -25 °C ... 85 °C (Cable, flexible installation) -40 °C ... 85 °C (cable, fixed installation) |

Standards and regulations

M12

| | |
|--------------------------|-----------------|
| Standard designation | M12 connector |
| Standards/specifications | IEC 61076-2-101 |

Mounting

| | |
|---------------|--------------|
| Mounting type | PCB mounting |
|---------------|--------------|

Packaging specifications

| | |
|-------------------|------|
| Type of packaging | Tray |
|-------------------|------|

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier


1414071

<https://www.phoenixcontact.com/us/products/1414071>



Drawings

Schematic diagram

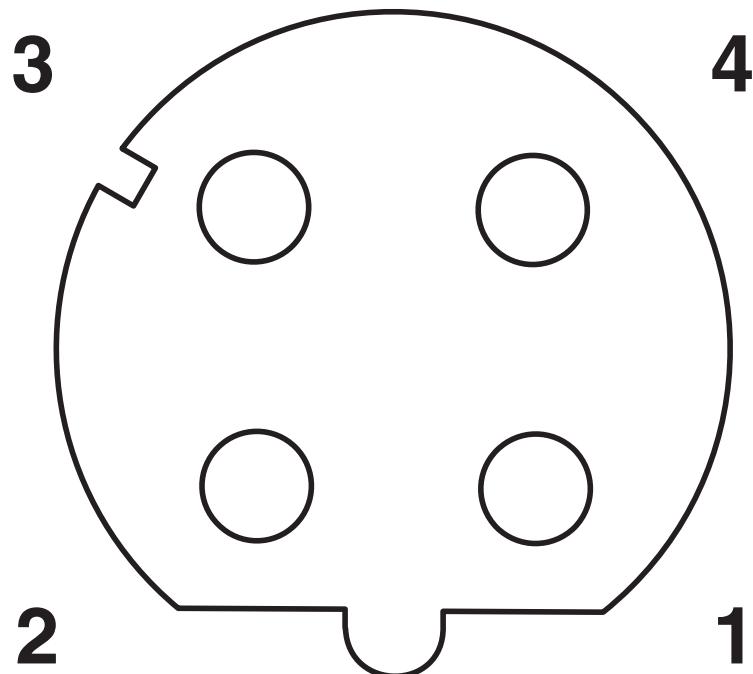

Pin assignment M12 socket, 4-pos., D-coded, female side

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



Approvals

ⓘ To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1414071>

| cUL Recognized | | | | |
|-------------------------------|-----------------------|-----------------------|-------------------|----------------------|
| Approval ID: E118976-20100522 | | | | |
| | Nominal voltage U_N | Nominal current I_N | Cross section AWG | Cross section mm^2 |
| | 250 V | 4 A | 22 - 22 | - |

| UL Recognized | | | | |
|-------------------------------|-----------------------|-----------------------|-------------------|----------------------|
| Approval ID: E118976-20100522 | | | | |
| | Nominal voltage U_N | Nominal current I_N | Cross section AWG | Cross section mm^2 |
| | 250 V | 4 A | 22 - 22 | - |

| cULus Recognized | | | | |
|------------------|--|--|--|--|
|------------------|--|--|--|--|

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-11.0 | 27440102 |
| ECLASS-12.0 | 27440116 |
| ECLASS-13.0 | 27460201 |

ETIM

| | |
|----------|----------|
| ETIM 9.0 | EC002637 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

Environmental product compliance

EU RoHS

| | |
|---|------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(c) |

China RoHS

| | |
|---|---------|
| Environment friendly use period (EFUP) | EFUP-50 |
| An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. | |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | 13944a28-6d85-4f54-b49a-1b148b63d5cc |

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



Accessories

PROT-M12 - Screw plug

1680539

<https://www.phoenixcontact.com/us/products/1680539>

An M12 screw plug for the unoccupied M12 sockets of the sensor/actuator cable, boxes and flush-type connectors



PROT-M12 SH - Screw plug

1503302

<https://www.phoenixcontact.com/us/products/1503302>

An M12 screw plug for the unoccupied M12 sockets of the shielded sensor/actuator cable, boxes and flush-type connectors



SACC-CI-M12FSD-4CON-L180 THR - Contact carrier



1414071

<https://www.phoenixcontact.com/us/products/1414071>

PROT-M12 FB - Screw plug

1555538

<https://www.phoenixcontact.com/us/products/1555538>



M12 high-grade steel screw plug, for unoccupied M12 sockets of the sensor/actuator cables, boxes and flush-type connectors for the food industry

SACC-CIM12FSD4PL180THRSAMPLE - Sample set

1413557

<https://www.phoenixcontact.com/us/products/1413557>



Bus system flush-type socket, Ethernet, 4-pos., D-coded, with straight THR solder connection, only contact insert

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier



1414071

<https://www.phoenixcontact.com/us/products/1414071>

SACC-M12-SCO NUT - Housing screw connection

1552243

<https://www.phoenixcontact.com/us/products/1552243>



Housing screw connection, Socket, M12-SPEEDCON, Front mounting, M12 x 1,
Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237399

SACC-DSIV-M12-NUT - Housing screw connection

1416144

<https://www.phoenixcontact.com/us/products/1416144>



Housing screw connection, Pin, M12, Front mounting, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239107

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier



1414071

<https://www.phoenixcontact.com/us/products/1414071>

SACC-M12-SCO NUT L 90 - Housing screw connection

1432460

<https://www.phoenixcontact.com/us/products/1432460>



Housing screw connection, M12-SPEEDCON, Front mounting, M12 x 1, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237409

SACC-BP-F-M12/M15-6-THR - Housing screw connection

1414004

<https://www.phoenixcontact.com/us/products/1414004>



Housing screw connection, Socket, M12, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239056

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



SACC-BP-F-M12/M15-7-THR - Housing screw connection

1414003

<https://www.phoenixcontact.com/us/products/1414003>



Housing screw connection, Socket, M12, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239055

SACC-BP-F-M12/M15-6-THR SCO - Housing screw connection

1414020

<https://www.phoenixcontact.com/us/products/1414020>



Housing screw connection, Socket, M12-SPEEDCON, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239057

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier



1414071

<https://www.phoenixcontact.com/us/products/1414071>

SACC-BP-F-M12/M15-7-THR SCO - Housing screw connection

1414005

<https://www.phoenixcontact.com/us/products/1414005>



Housing screw connection, Socket, M12-SPEEDCON, Rear mounting, M15 x 1, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237398

SACC-BP-F-M12/THR-1,0/1,8-9TIP - Housing screw connection

1419630

<https://www.phoenixcontact.com/us/products/1419630>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 1.0 mm ... 1.8 mm thick front plates.

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



SACC-BP-F-M12/THR-1,7/2,5-9TIP - Housing screw connection

1419631

<https://www.phoenixcontact.com/us/products/1419631>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 1.7 mm ... 2.5 mm thick front plates.

SACC-BP-F-M12/THR-2,4/3,2-9TIP - Housing screw connection

1419633

<https://www.phoenixcontact.com/us/products/1419633>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 2.4 mm ... 3.2 mm thick front plates.

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier



1414071

<https://www.phoenixcontact.com/us/products/1414071>

SACC-BP-F-M12/THR-3,1/3,9-9TIP - Housing screw connection

1419634

<https://www.phoenixcontact.com/us/products/1419634>



M12 threaded sleeve with tolerance-compensating function, for straight, THR solderable M12 socket contact inserts. Suitable for 3.1 mm ... 3.9 mm thick front plates.

SACC-M12 NUT PRESS - Housing screw connection

1437889

<https://www.phoenixcontact.com/us/products/1437889>



Housing screw connection, Socket, M12, Front mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1237410

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



SACC-DSIV-M12-NUT-9 THR - Housing screw connection

1417989

<https://www.phoenixcontact.com/us/products/1417989>



Housing screw connection, Front mounting, THR solder connection, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1239181

SACC-BP-F-M12-THR PP - Housing screw connection

1027662

<https://www.phoenixcontact.com/us/products/1027662>



Housing screw connection, Socket, M12-Push-pull external locking, Rear mounting, M16, THR- und Wellenlötkontakte, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

SACC-CI-M12FSD-4CON-L180 THR - Contact carrier

1414071

<https://www.phoenixcontact.com/us/products/1414071>



SACC-FP-F-M12-THR PP - Housing screw connection

1027678

<https://www.phoenixcontact.com/us/products/1027678>



Housing screw connection, Socket, M12-Push-pull external locking, Front mounting, M14 x 1, THR- und Wellenlötkontakte, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com