


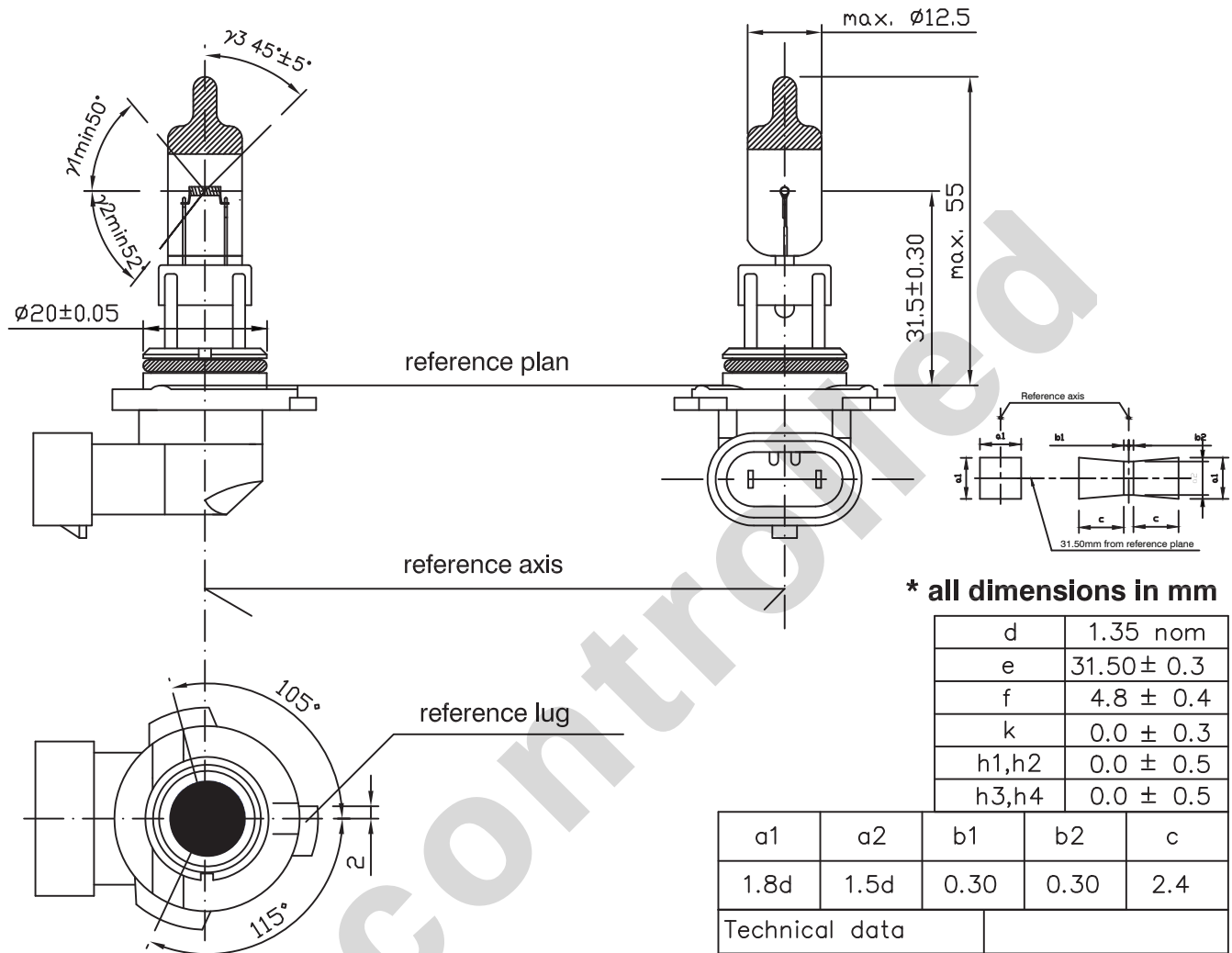

* all dimensions in mm

d	1.35 nom
e	31.50 ± 0.3
f	4.8 ± 0.4
k	0.0 ± 0.3
h1,h2	0.0 ± 0.5
h3,h4	0.0 ± 0.5

a1	a2	b1	b2	c
1.8d	1.5d	0.30	0.30	2.4

Technical data	
Test voltage	12.8V
Power	43W max
Luminous flux	600lm ±15%
Lumen maintenance after 200hr	90 % min
Rated life: ²⁾³⁾	at 14.0V
-B70	550hr
-B50	500hr
-B10	320 hr

Halogen bulb

9040 12V 40W

Cap: ¹⁾ P20d/40T

Type: 9040

ECE R37 none

FMVSS108 none

Bulb mat.: Hardglass

1) According to IEC 60061-1 sheet 7004-31-2

2) According to SAE J 1383 Annex 5.20

3) Switching cycle according to SAE J 1383 5.20.2

4) According to IEC 60810 Annex A

5) Switching cycle according to IEC 60810 Annex A;4.1.1

6) Switching cycle according to IEC 60810 Annex A;4.1.2

7) Switching cycle according to IEC 60810 Annex A;4.2

Maximum operating temperature: bulb 650°C max
pinch 400°C max
Operating position horizontal

Vibration resistance acc. to IEC 60810 Annex B; table B.2 > 20h