


Part Number : 428171114

Product Description : Mini-Fit Sr. Crimp Terminal, Male, 12-10 AWG, Silver (Ag)

Series Number : 42817

Status : Active

Product Category : Crimp Terminals

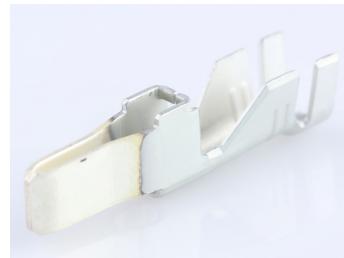

## Documents & Resources

### Drawings

[Drawing 428171114\\_sd.pdf](#)

[Packaging Design Drawing PK-42815-001-001.pdf](#)

### Specifications

[Application Specification AS-42815-001-001.pdf](#)

[Product Specification PS-42815-001-001.pdf](#)

[Test Summary TS-42815-004-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

### Part Details

#### General

Status	Active
Category	Crimp Terminals
Series	42817
Description	Mini-Fit Sr. Crimp Terminal, Male, 12-10 AWG, Silver (Ag)
Application	Power, Wire-to-Wire
Comments	High Current/Low Force; See Product Specification for maximum current rating by circuit size and application.
Product Family	Mini-Fit Sr. Power Connectors
Product Name	Mini-Fit Sr.
UPC	889056244787

#### Electrical

Current - Maximum per Contact	50.0A
-------------------------------	-------

#### Physical

Gender	Male
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Silver
Material - Plating Termination	Tin
Net Weight	1.503/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	5.30mm max.
Wire Size (AWG)	10, 12
Wire Size mm <sup>2</sup>	N/A

## Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

---

## Use with Part(s)

Description	Part Number
10.00mm Pitch Mini-Fit Sr. Single Row Plug Housings	<u>42818</u>
Mini-Fit Sr. Dual Row Plug Housings	<u>43938</u>

---

## Application Tooling

### Global

Description	Part Number
Hand Crimp Tool for 10.00mm Pitch Mini-Fit Sr. Crimp Terminals, 12-10 AWG	<u>2002188600</u>
FineAdjust Applicator for Insulation OD 4.40-5.30mm, 12-10 AWG	<u>2037022700</u>
FineAdjust Applicator for Insulation OD 3.50-4.40mm, 12-10 AWG	<u>2037022800</u>
Extraction Tool for Mini-Fit Sr. Terminals, 16-8 AWG	<u>638130400</u>
FineAdjust Applicator for Insulation OD 4.30-5.00mm, 5.00-6.00mm <sup>2</sup>	<u>639040200</u>

---

This document was generated on Sep 23, 2024