

Actuator

45-
2231.22H0.000



<https://eao.com/p/45-2231.22H0.000>

Your product:



45-2231.22H0.000 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front bezel colour:	Silver
Front bezel material:	Metal

MOUNTING

Design:	raised
----------------	--------

OPERATING-/INDICATION PART

Lens illumination:	illuminative
Lens colour:	Green
Lens shape:	flush
Lens material:	Plastic
Lens optics:	transparent
Illumination colour:	Green

MECHANICAL CHARACTERISTIC


Weight:	0.04 kg
Switching action:	Momentary
Switching system:	Slow-make switching element
Mechanical lifetime:	3 Mio. cycles of operation
Operating frequency:	Max. 3 600/h

AMBIENT CONDITION


IP front protection:	IP66, IP67, IP69K
Operating temperature:	- 25 °C ... + 70 °C
Storage temperature:	- 40 °C ... + 80 °C
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
Vibration resistance:	According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

OTHER


Housing colour:	Silver
Housing material:	Metal
Short Description:	Actuator, Ø 29,5 mm, flush, illuminative, Green, Plastic, transparent, Silver, Metal, Momentary, IP66, IP67, IP69K, Green
Mounting cut-outs:	

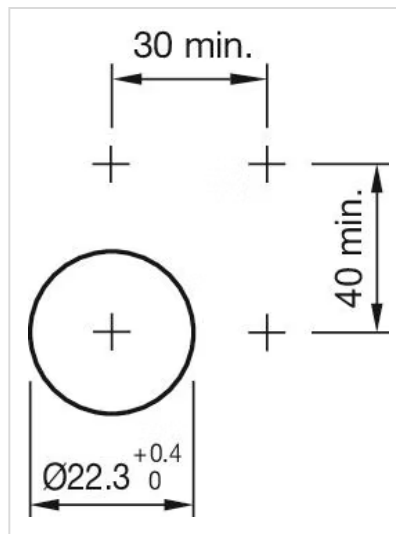

Wiring diagrams:

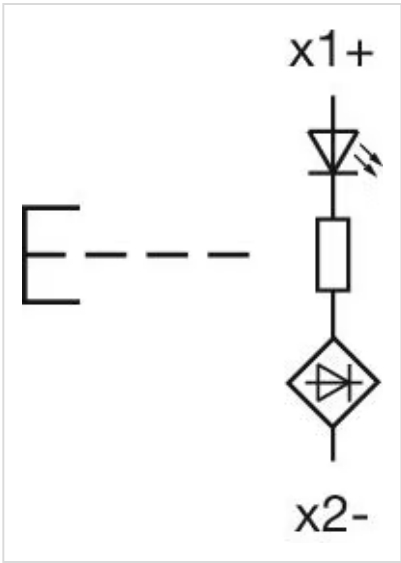

Dimension drawings:

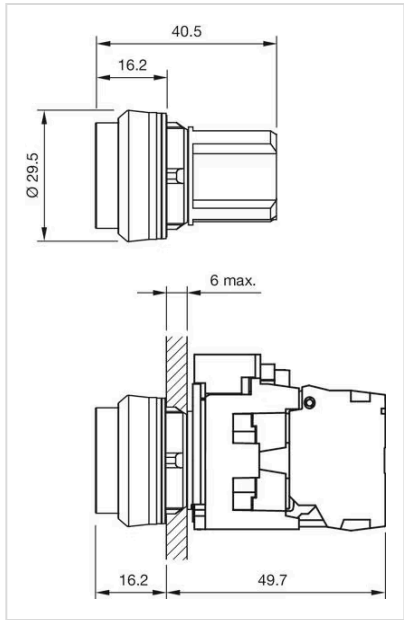

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2231.22H0.000](#)