



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1452426-1
EXTRACTION TOOL



TE Part # 6-1579007-1
EXTRACTION TOOL



TE Part # 5-963716-1
MQS0,63 Sn tab LL unseal. 0,5-0,75



TE Part # 1-1418664-2
10 POS MQS PIN HSG FOR LVDS



TE Part # 2063525-1
SDE MQS 0.5-0.75mm2 ASSY



TE Part # 2063525-2
SDE MQS 0.5-0.75mm2 DIE SET



TE Part # 2390077-1
SDE F MQS PIN/SKT 0.75-0.50mm2 ASSY



TE Part # 2390077-2
SDE F MQS PIN/SKT 0.75-0.50mm2 DIE SET



TE Part # CAT-M8793-CH8172
MQS, CONNECTOR HOUSING

Customers Also Bought




TE Part #5177983-6
0.8FH,R05H.5,140,08/Sn,TU



TE Part #953698-1
MQS, CONNECTOR HOUSING



TE Part #SRK02-MDA-32A-001
REC, 32P, BLK, E, FLANGE, A

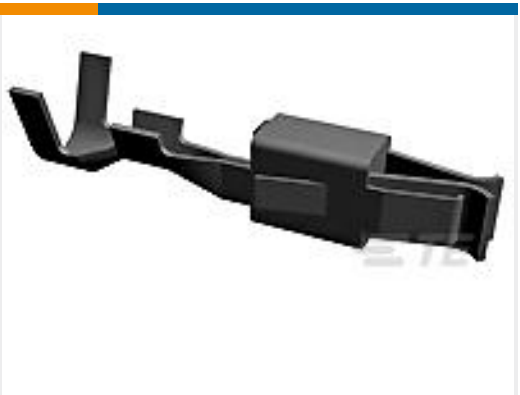

TE Part #929940-6
JPT REC 2.8 Contact SWS Ag (LP)



TE Part #1-1768020-5
ESSW41-052



TE Part #K1160725
Push button switch TS-211-RT42



TE Part #1-968873-3
AMP MCP 2.8, CONTACT (LP)

Documents



CAD Files

Customer View Model

ENG_CVM_CVM_963730-1_W.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_963730-1_W.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_963730-1_W.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English