

PVT2 PHOTOVOLTAIC SURGE PROTECTION CLASS II, 1,500 VDC UCPV

CATALOG NUMBER

PVT21500R



CERTIFICATIONS



FEATURES

Suited for use at the DC input of distributed string inverters in solar arrays

Thermal protection included to ensure safe failure modes

Compact, yet high surge rated pluggable design, using minimum DIN rail width

PRODUCT ATTRIBUTES

Max Continuous Operating Voltage (Ucpv): 1500

Nominal Discharge Current (In), IEC: 20kA 8/20 μ s

Max Discharge Current (Imax): 30kA 8/20 μ s

Total Discharge Current (Itotal): 40

Voltage Protection Level (Up): 5000V

Response Time: 25 ns Max

Short Circuit Current Rating (Iscrr): 11kA

Max Continuous Operating Voltage (Vpvdv): 1,500 VDC

Voltage Protection Rating (VPR): 4000V

Nominal Discharge Current (In), UL: 20kA 8/20 μ s

Short Circuit Current Rating (SCCR): 65kA

Protection Modes: -ve to PE;-ve to +ve;+ve to PE

Altitude: 6562' Max

Humidity: 5 - 95

Temperature: -40 to 185 °F

Connection, Flexible: #4

Connection, Solid: #2

Connection, Stranded: #2

Enclosure Material: UL® 94V-0 Thermoplastic

Enclosure Rating: IP 20

Mounting: 35 mm top hat DIN rail

Torque (TQ): 3.3 ft·lbf Max

Remote Contact Switching Capacity: 1 A @ 125 VAC; 1 A @ 250 VAC; 0.5 A @ 12 VDC; 0.5 A @ 24 VDC; 0.5 A @ 48 VDC

Remote Contacts: Yes

Status Indication: Mechanical flag

Depth (D): 2.72"

Height (H): 3.54"

Width (W): 2.13"


Unit Weight: 1 lb

Replacement Module: PVT2750M

Certification Details: UL® 1449 Edition 4 Type 1CA

Complies With: EN 50539-11 Type 1, Type 2

DIAGRAMS

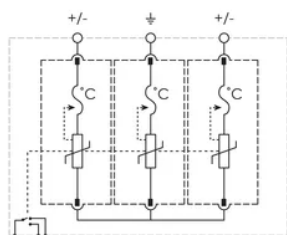

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



nVent.com

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF

TRACER