



Connectors > Connector Accessories > Connector Strain Relief > CPC Cable Clamps



Strain Relief Accessory Type: Cable Clamp Kit

Primary Product Material: Nylon

Primary Product Color: Black

Compatible With Connector Shell Size: 17

Cable Entry Diameter: 11.51 mm [.453 in]

[All CPC Cable Clamps \(25\)](#)

Features

Product Type Features

Strain Relief Accessory Type	Cable Clamp Kit
------------------------------	-----------------

Body Features

Primary Product Material	Nylon
Primary Product Color	Black

Mechanical Attachment

Thread Size	15/16-20 UNEF-2B
-------------	------------------

Housing Features

Compatible With Connector Shape	Circular
Body Orientation	Right Angle

Dimensions

Cable Entry Diameter	11.51 mm[.453 in]
----------------------	-------------------

Operation/Application

--	--



Compatible With Connector Shell Size	17
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Method	Individual
Packaging Quantity	1

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-AM71-C83998J
Cable/Panel Mount Connector, CPC Series 1



TE Part # CAT-AM71-C83998M
CPC Connectors, Series 2



TE Part # 1-207369-1
CPC RECEPT ASSY SIZE 17-28 LF



TE Part # CAT-AM71-C83998BB
CPC SERIES 3



TE Part # CAT-AM71-C83998F
Connectors with Posted Pin Contacts, CPC Series 1



TE Part # CAT-AM71-C83998Y
One-Piece Connector, Sealed, CPC Series 1



TE Part # 206044-1
CPC PLUG ASSEMBLY SIZE 17-14



TE Part # CAT-AM71-C83998DD
Connectors, CPC Series 2, with Posted Contacts



TE Part # 1-207369-3
CPC RECEPT ASSY SZ 17-28 LF



TE Part # 1776904-1
CPC POSTED RCPT, 17-16, R/A

Also in the Series | AMP CPC



Circular Power Connectors(458)



Connector Backshells(1)



Connector Caps & Covers(19)



Connector Contacts(6)




Connector Hardware(12)




Connector Seals & Cavity Plugs(36)



Connector Strain Relief(60)

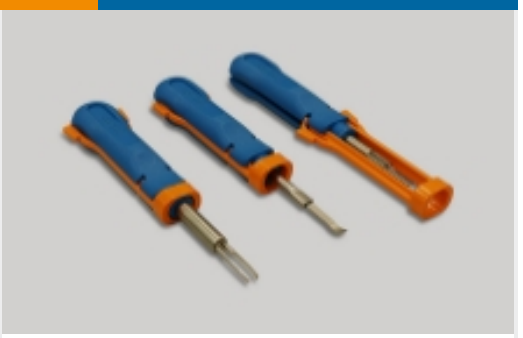


Insertion & Extraction Tools(1)

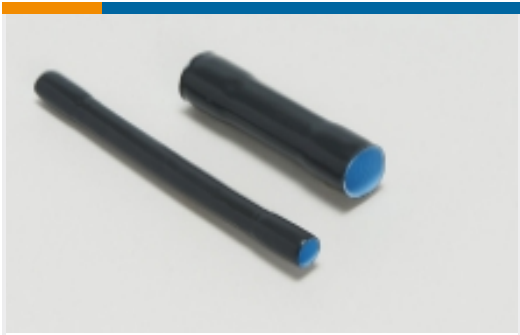

Sealing Sleeves(2)


Customers Also Bought

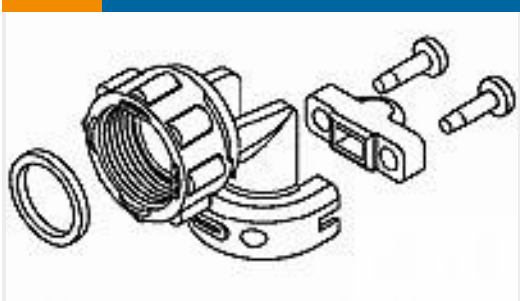

TE Part #796380-2
R/A STRN RELIEF KIT,SZ 13,CPC



TE Part #SP1-4
STRING POT 4.75 INCH RANGE

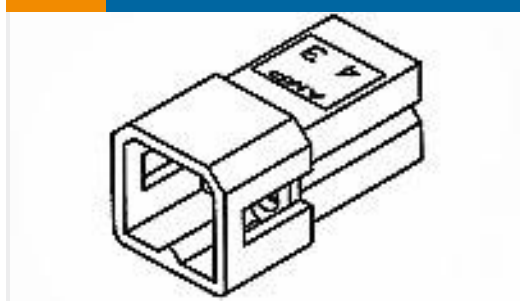

TE Part #770428-1
09P .062 COMM P&S PLUG



TE Part #7-1393118-0
KUP-5D55-12=KU



TE Part #2362760-1
IDC PLUG, Die Cast




TE Part #2180013004
55A0811-22-9




TE Part #3234330001
RPS-1K-16-10/2.0-4



TE Part #1766232-1
CONTACT,PIN, .25 DIA

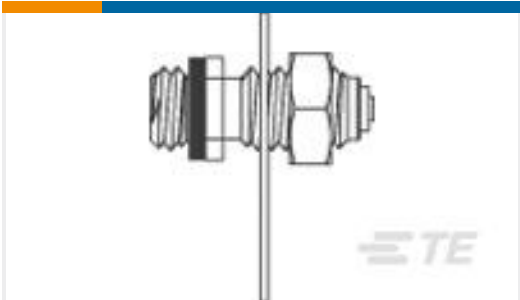

TE Part #1466287-1
031-0003-0001

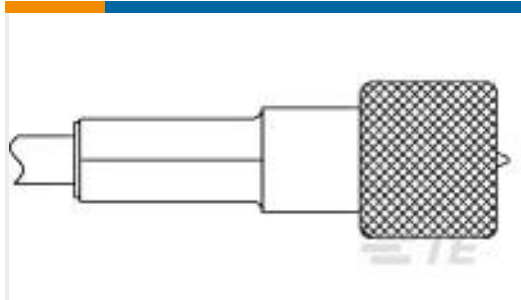

TE Part #1466328-1
132-0115-0002=PLUG,STR GC-50

Documents

Product Drawings

R/A STRN RELIEF KIT,SZ 17,CPC

English

CAD Files

Customer View Model

ENG_CVM_CVM_796381-2_D.2d_dxf.zip

English

3D PDF



3D

Customer View Model

[ENG_CVM_CVM_796381-2_D.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_796381-2_D.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.