




Connectors > D-Shaped Connectors > D-Sub Connectors > Crimp D-Sub Connectors >

D-Sub Crimp Recpt Signal 15 Posn, Socket Size 20, Shell Size 2

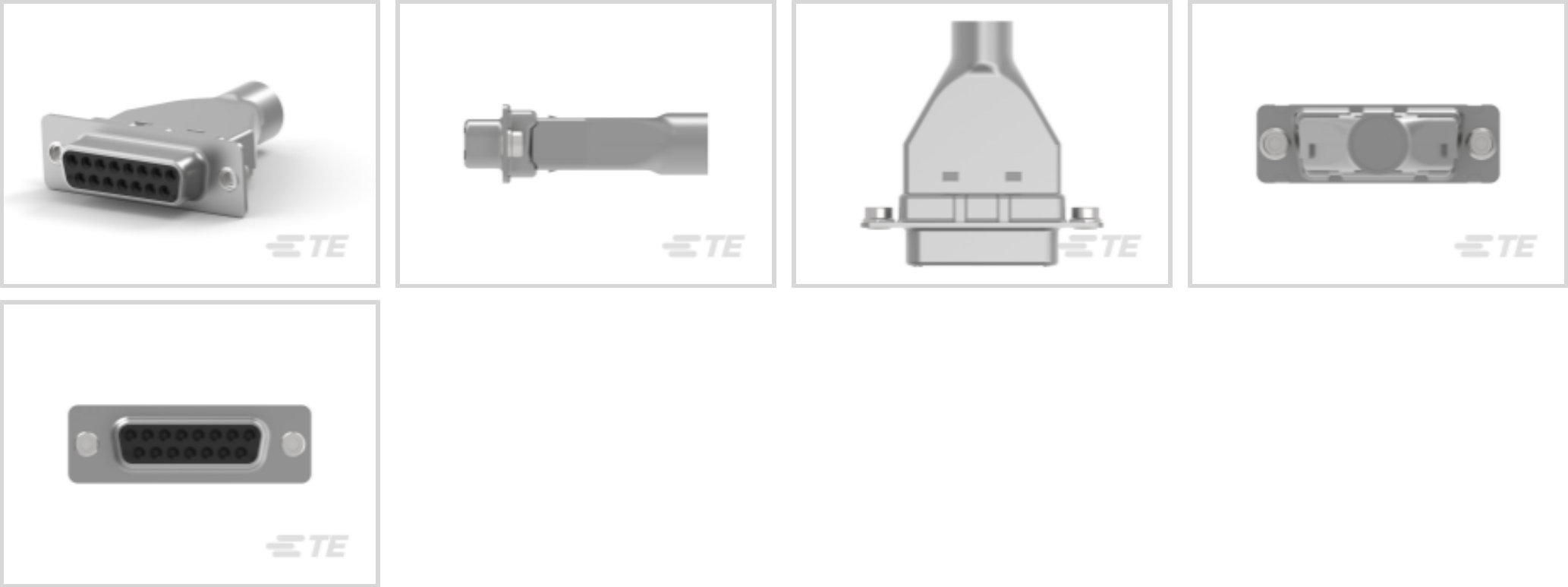

Connector & Housing Type: **Receptacle**

Connector System: **Cable-to-Cable**

Number of Positions: **15**

Contact Size: **Size 20**

Connector Shell Size: **2**

[All D-Sub Crimp Recpt Signal 15 Posn, Socket Size 20, Shell Size 2 \(10\)](#)

Features

Product Type Features

Shell Material Configuration	Full Metal Shell
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Connector System	Cable-to-Cable
Connector Shell Size	2
Sealable	No

Configuration Features

Number of Positions	15
---------------------	----

Body Features

Insert Material	Thermoplastic
Shield Plating Material	Tin
Shield Material	Steel



Shell Plating Material	Tin over Copper
Primary Product Color	Black
Contact Features	
Contact Options	Order Separately
Contact Size	Size 20
Termination Features	
Termination Method to Wire & Cable	Crimp
Mechanical Attachment	
Mating Retention	With
Mating Retention Type	Clinch Nut, 4-40 UNC
Housing Features	
Shell Material	Steel
Housing Material	Nylon GF
Centerline (Pitch)	2.74 mm[.108 in]
Dimensions	
Compatible Insulation Diameter Range	4.83 – 8.38 mm
Usage Conditions	
Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Operation/Application	
Circuit Application	Signal
Shielded	Yes
Industry Standards	
UL Flammability Rating	UL 94V-0
Packaging Features	
Packaging Quantity	1
Packaging Method	Kit, Package
Product Compliance	
For compliance documentation, visit the product page on TE.com>	
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant



China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-035-DCPPS202
D-Sub Crimp: Plug, Signal, 15 Posn, Pin Size 20, Shell Size 2



TE Part # CAT-035-DCRSS202
D-Sub Crimp Recpt Signal 15 Posn, Socket Size 20, Shell Size 2

Customers Also Bought




TE Part #66504-4
D-Sub Conn Contacts: Socket, Phosphor Bronze, Signal, Size 20




TE Part #5-1478762-3
Metal backshell 25 way Top Ent



TE Part #5-747904-5
9 Plug Solder Cup, 30 gold, Ro

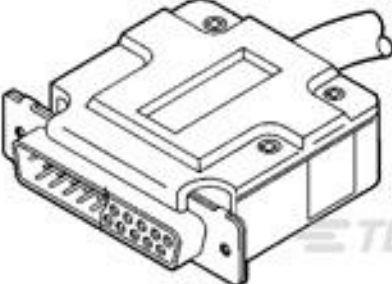


TE Part #207470-1
CABLE CLAMP KIT,SZ 2

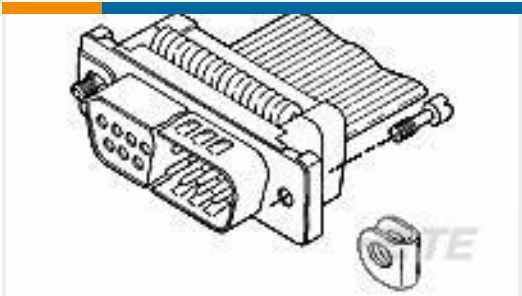


TE Part #5746881-1
MALE SCREW RETAINER KIT




TE Part #5745563-3
HD KIT,SCREWLOCK

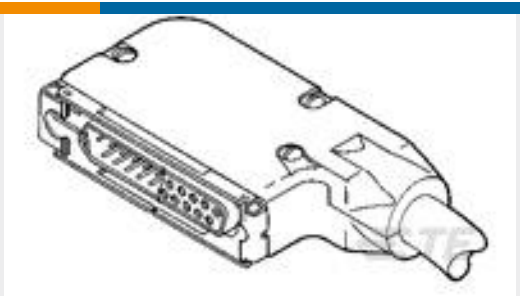

TE Part #5745653-3
DIECAST STRAIN RELIEF KIT,SZ 3

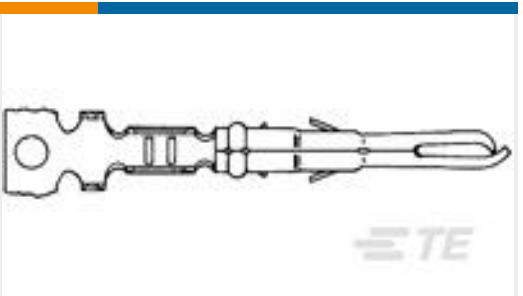

TE Part #640579-2
MR SPLIT PIN AUPHBRZ LP 26-24

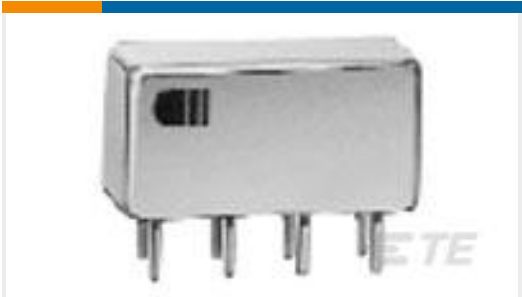

TE Part #3-1617029-3
HFW1131K04M = M39016/6-107M

Documents

Product Drawings

KIT,RCPT,15P,HDP-20,SHLD HDWRE

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5787908-1_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5787908-1_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5787908-1_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Specifications

Application Specification

English



Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

CSA Certificate

English