



R2A20117SP

Products

Analog & Mixed signal

Power Management

ICs for PFC Power Supply

R2A20117SP


OverviewDocumentationDesign Support

- Product Spec
- Order Information
- Contact
- Package & Packing


Product Spec

Star Product	-
Package Type	SOP
Pin Count	16
Function	PFC control IC
Icc (mA) typ.	7.3
Vin (V) max.	24
Topa[Tjopa] (degC) min.	-40
Topa[Tjopa] (degC) max.	150
Tstg (°C) min.	-55
Tstg (°C) max.	150
Production Status	Non-promotion

Pin Assignment

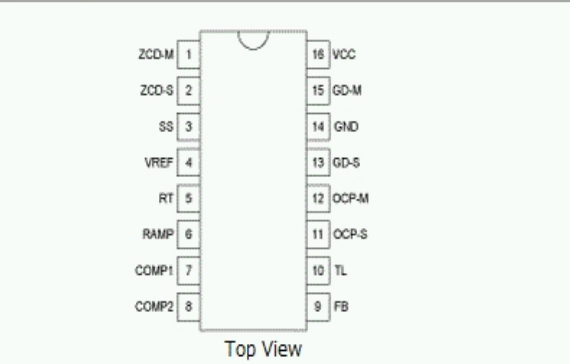

Dimensions

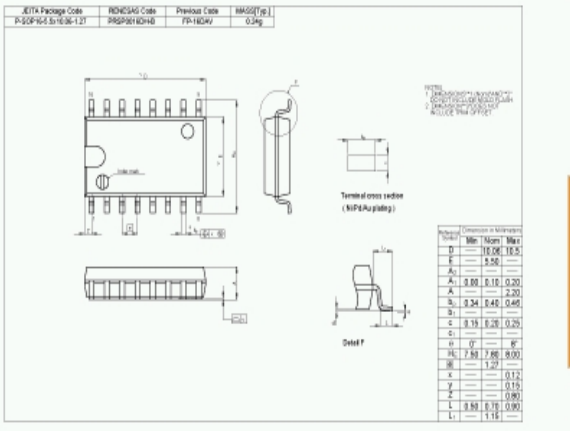

Back To Top

Order Information

Orderable Part No.	Order	Production Status	Packing	MOQ	EU RoHS	RoHS-pdf (China-RoHS)
R2A20117SP#U0	Contact	Mass Production	Tube	-	Compliant	English
R2A20117SP#W0	Contact	Mass Production	Embossed Tape	2000	Compliant	English

Back To Top

Package & Packing

Package	
Name	SOP
JEITA code	P-SOP16-5.5x10.06-1.27
Previous code	FP-16DAV
Renesas code	PRSP0016DH-B
Terminal count	16
Terminal pitch (mm)	1.27
Dimensions (mm)	5.5x10.06
Mass (g)(TYP.)	0.24
Drawing Link	prsp0016dh_b
Mount pad	fig0001e

Packing		
Packing	Tape No dry pack	tape-ND
Container	Tape	tape2048
	Tube No dry pack	mag0026_mag0038
Packing	Tube No dry pack	mag-ND

Back To Top