

1.25 mm [.049] FP Connectors (Continued)

1.25 mm Dual-Row, Standard, Receptacle Headers — Vertical Mounting for Parallel Board Connection




Material and Finish

Housing — Polyphenylene sulfide, black, UL 94V-0 rated

Contact — Phosphor bronze, 0.30 [.012] thick, tin-lead plated

Related Product Data

Mates with — Post Headers, page 115

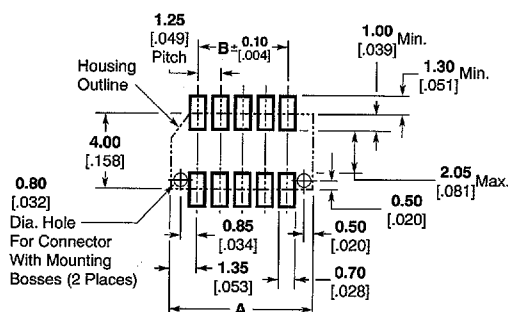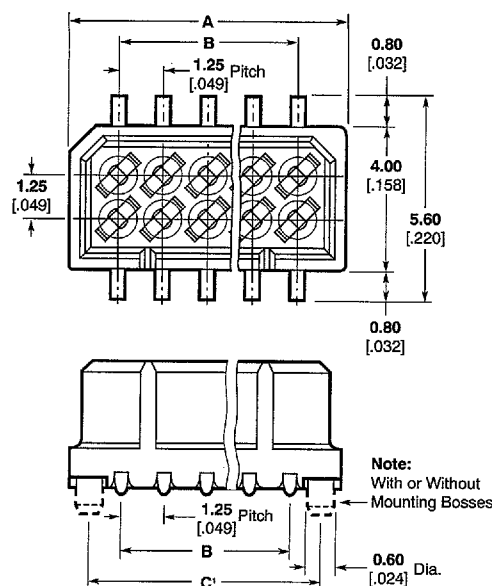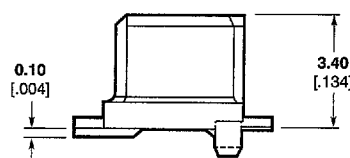

Recommended PC Board Layout

No. of Pos.	Dimensions			Part Numbers			
	A	B	C ¹	With Mounting Bosses		Without Mounting Bosses	
				Loose Piece	Reel Mounted ²	Loose Piece	Reel Mounted ²
6	5.20 .205	2.50 .098	4.20 .165	3-174639-6	3-175638-6	—	3-175630-6
10	7.70 .303	5.00 .197	6.70 .264	4-174639-0	4-175638-0	4-174904-0	4-175630-0
12	8.95 .352	6.25 .246	7.95 .313	4-174639-2	4-175638-2	4-174904-2	4-175630-2
14	10.20 .402	7.50 .295	9.20 .362	4-174639-4	4-175638-4	4-174904-4	4-175630-4
16	11.45 .451	8.75 .345	10.45 .411	4-174639-6	4-175638-6	4-174904-6	4-175630-6
18	12.70 .500	10.00 .394	11.70 .461	4-174639-8	4-175638-8	4-174904-8	4-175630-8
20	13.95 .549	11.25 .443	12.95 .510	5-174639-0	5-175638-0	5-174904-0	5-175630-0

¹"C" dimension used **only** with Receptacle Headers with Mounting Bosses.

Packaging Quantities, Reel — 1,500 per reel for Positions 6 thru 14; 1,000 per reel for Positions 16 thru 20