

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2138651635

Status:


Active

Overview:

Temperature Sensor Cable Assemblies

Description:

NTC Ring Temperature Sensor-to-Micro-Lock Plus Cable Assembly, 150.00mm Length, 3982 Beta Value, 10k# Resistance at 25°C with 1% Tolerance, Black

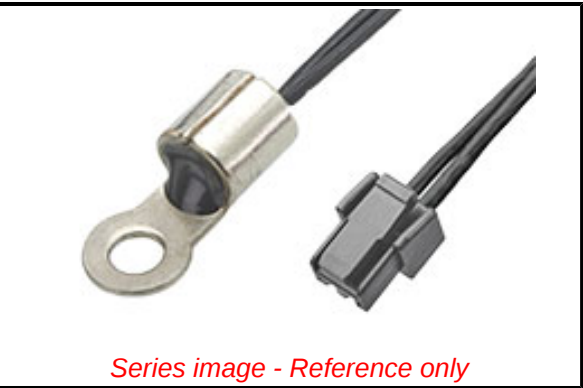

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

|                            |                                     |
|----------------------------|-------------------------------------|
| General                    |                                     |
| Product Family             | Cable Assemblies                    |
| Series                     | 213865                              |
| Application                | Temperature Sensing                 |
| Assembly Configuration     | Dual Ended Connectors               |
| Beta Value (K)             | 3982                                |
| Connector to Connector     | Ring Term-to-Micro-Lock Plus        |
| Overmolded                 | No                                  |
| Overview                   | Temperature Sensor Cable Assemblies |
| Product Name               | NTC Ring Temperature Sensor         |
| Resistance Tolerance (%)   | 1                                   |
| Resistance at 25°C (kohms) | 10                                  |
| Stud Size                  | 6 (M3.5)                            |
| Type                       | Discrete Wire Assembly              |
| UPC                        | 193264540433                        |

|                                |                      |
|--------------------------------|----------------------|
| Physical                       |                      |
| Cable Length                   | 150.00mm             |
| Circuits (Loaded)              | 2                    |
| Color - Resin                  | Black                |
| Gender                         | Female-Female        |
| Lock to Mating Part            | Yes                  |
| Material - Metal               | Copper Alloy         |
| Material - Plating Mating      | Nickel               |
| Material - Plating Termination | Nickel, Tin          |
| Material - Resin               | PBT                  |
| Net Weight                     | 2.132/g              |
| Number of Rows                 | 1                    |
| Packaging Type                 | Bag                  |
| Pitch - Mating Interface       | 1.25mm               |
| Single Ended                   | No                   |
| Termination Interface: Style   | Crimp or Compression |
| Wire Insulation Diameter       | 0.95mm               |
| Wire Size AWG                  | 26                   |
| Wire/Cable Type                | PTFE, UL 10344       |

|                               |                 |
|-------------------------------|-----------------|
| Electrical                    |                 |
| Current - Maximum per Contact | 0.5A            |
| Voltage - Maximum             | 50V AC (RMS)/DC |

Material Info

|                             |                |
|-----------------------------|----------------|
| Reference - Drawing Numbers |                |
| Sales Drawing               | 2138601633-000 |

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 15

REACH SVHC

Contained Per - D(2020)4578-DC (25 June 2020)  
Lead

Halogen-Free Status

Not Reviewed

For more information, please visit [Contact US](#)

|                 |               |
|-----------------|---------------|
| China ROHS      | 50 Image      |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

213865 Series

Mates With

Micro-Lock Plus Vertical Header [505568](#)  
<br> Micro-Lock Plus Right Angle Header [505567](#)

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**