


Double-Gang Surface-Mount Back Box, White, TAA

MODEL NUMBER: **N080-SMB2-WH**

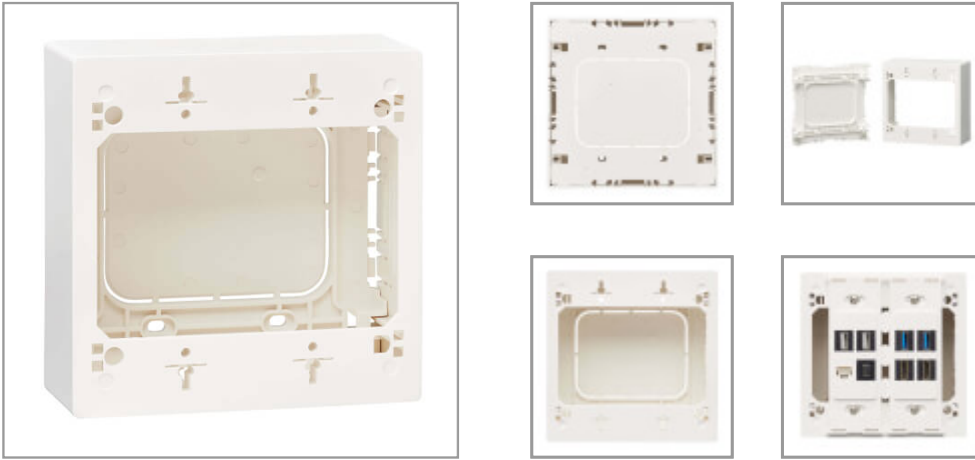

Deep double-gang junction box mounts a wall plate to complete multiple audio/video, voice and/or Ethernet in-wall connections.

Features

Double-Gang Surface-Mount Junction Box for Premise ApplicationsThe N080-SMB2-WH is ideal for mounting a double-gang wall plate to complete multiple audio/video, voice and Ethernet in-wall connections using any type of keystone jack, including Cat5e/6/6a, USB, HDMI, DisplayPort and RCA. Designed to work with mid-sized and standard double-gang wall plates, this back box is two inches deep.

Raceway Cutouts on Each Side for Easy AccessThe N080-SMB2-WH features raceway cutouts in three different sizes (1 inch, 1.25 inches and 1.75 inches in diameter) on each side, as well as a rectangular knockout on the back. The cover snaps securely to the base with no screws required.

Highly Adaptable to Match Your Specific RequirementsMade from robust ABS thermoplastic, the N080-SMB2-WH is colored white to blend elegantly into any home or office decor for a sleek, professional installation. Four mounting screws are included.

TAA-Compliant for GSA Schedule PurchasesThe N080-SMB2-WH is compliant with the Federal Trade Agreements Act (TAA), which makes it eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.

Highlights

- Mid-sized back box accommodates any mid-sized or standard double-gang wall plate
- High-impact ABS thermoplastic construction designed to last a long time
- Classic white color blends elegantly into your home or office décor
- Raceway cutouts in 3 different sizes at each panel allow bulk cabling
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Applications

- Complete multiple in-wall audio/video, voice and/or Ethernet cable lines simultaneously

Package Includes

- N080-SMB2-WH Double-Gang Surface-Mount Junction Box
- (4) #6-20 wood screws
- (4) 2-sided adhesive strips

Specifications

| OVERVIEW | |
|----------------|--|
| UPC Code | 037332236272 |
| Accessory Type | Wall Plate |
| Technology | Cat5/5e; Cat6; Cat6a; USB 2.0 (High Speed); HDBaseT; HDMI; DisplayPort |
| Country/Region | Global |
| CONNECTIONS | |



Powering Business Worldwide



| | |
|--------------------------------------|------------------------------|
| Side A - Connector 1 | KEYSTONE JACK CUTOUT |
| Side B - Connector 1 | KEYSTONE JACK CUTOUT |
| PHYSICAL | |
| Color | White |
| Total Number of Ports | 0 |
| Shipping Dimensions (hwd / in.) | 12.00 x 10.00 x 0.50 |
| Shipping Dimensions (hwd / cm) | 30.48 x 25.40 x 1.27 |
| Shipping Weight (lbs.) | 0.39 |
| Shipping Weight (kg) | 0.18 |
| Unit Dimensions (hwd / in.) | 5.060 x 5.080 x 2.130 |
| Unit Dimensions (hwd / cm) | 128 x 8 x 5 |
| Unit Weight (lbs.) | 0.27 |
| Unit Weight (kg) | 0.12 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 14° to 140°F (-10° to 60°C) |
| Storage Temperature Range | -40° to 154°F (-40° to 68°C) |
| Relative Humidity | 10% to 90% RH |
| FEATURES & SPECIFICATIONS | |
| Antibacterial | No |
| STANDARDS & COMPLIANCE | |
| Product Compliance | Trade Agreements Act (TAA) |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.