



Positive Lock | Positive Lock 250

TE Internal #: 927852-7

Receptacle, 20 – 17 AWG Wire Size, .51 – 1.03 mm² Wire Size,
Mating Tab Width 6.35 mm [.25 in], Straight, Positive Lock 250,
Quick Disconnects

[View on TE.com >](#)

Terminals & Splices > Quick Disconnects



Quick Disconnect Terminal Type: **Receptacle**

Wire Size: **.51 – 1.03 mm²**

Mating Tab Width: **6.35 mm [.25 in]**

Mating Tab Thickness: **.81 mm [.032 in]**

Features

Product Type Features

Insertion Force	Low
-----------------	-----

Configuration Features

Connection Capacity	Single
Compatible With Wire & Cable Type	FLK

Contact Features

Quick Disconnect Terminal Type	Receptacle
Mating Tab Width	6.35 mm[.25 in]
Mating Tab Thickness	.81 mm[.032 in]
Terminal Orientation	Straight
Contact Base Material	Phosphor Bronze
Terminal Plating Material	Pre-Tin
Crimp Type	F-Crimp
Barrel Type	Open

Termination Features

--	--



Product Terminates To	Wire & Cable
-----------------------	--------------

Mechanical Attachment

Extraction Force	7 – 100 Newton
Wire Insulation Support	With
Mating Retention Type	Dimple

Dimensions

Terminal Material Thickness	.41 mm[.016 in]
Product Length	22.3 mm[.878 in]
Compatible Insulation Diameter Range	1.4 – 2.31 mm[.055 – .091 in]
Wire Size	.51 – 1.03 mm²

Usage Conditions

Insulation Option	Uninsulated
Operating Temperature Range	-40 – 110 °C[-40 – 230 °F]

Industry Standards

Compatible With Agency/Standards Products	UL
---	----

Packaging Features

Packaging Quantity	1500
Packaging Method	Strip/Reel

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer



This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-T4827-CH8172
Timer Connector Housing



TE Part # 724659-2
EXT TOOL FOR POSITIVE .250



TE Part # 2151161-2
OCEAN_2.0_APPLICATOR-S-081F110OVA-RSA




TE Part # 2305570-1
Strip Terminal Cutter-Side Feed-No Crimp




TE Part # 7-2151161-7
OCEAN_2.0_SPARE_PART_KIT-081F110OV




TE Part # 169400
CERTI-LOK FRAME W/O DIES

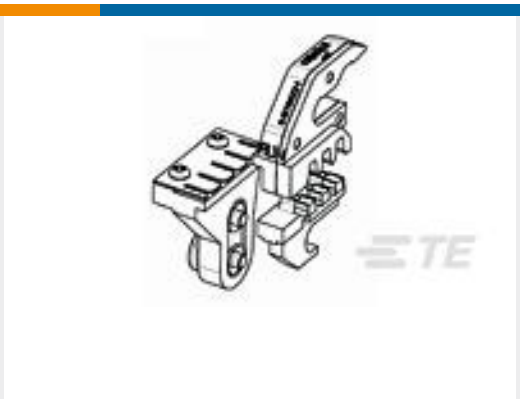

TE Part # 734469
MATRIZENPAAR

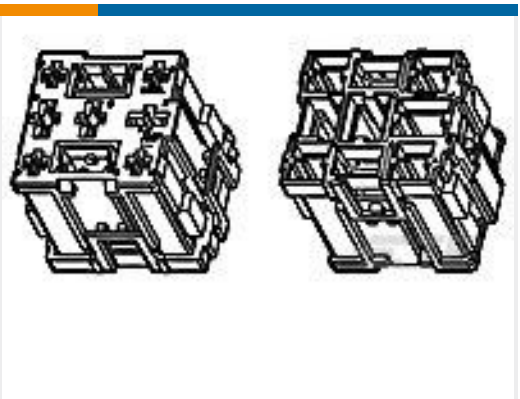

TE Part # 1-444017-1
HSG ASSY TIMER 9P

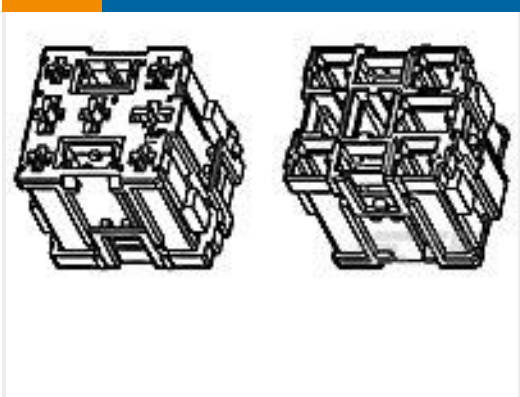

TE Part # 444017-2
HSG ASSY 9 POS JR

Also in the Series | Positive Lock 250



Automotive Terminals(1)



Crimp Terminal Housings(190)



Insertion & Extraction Tools(3)



Insulation Boots & Sleeves(4)



Quick Disconnects(185)


Customers Also Bought



TE Part #0021036002
RBK-ILS-125-NR3-0-50MM




TE Part #2-1393302-3
V23134A0052G243-EV-CBOX

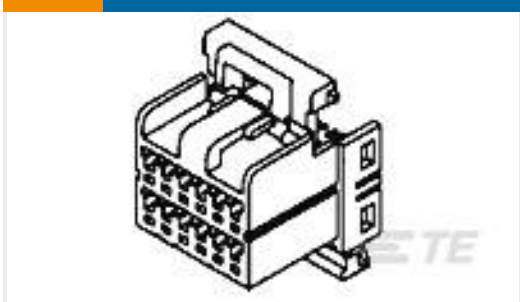

TE Part #174047-1
040 MLC PLUG HSG 20P NATURAL



TE Part #2209954-1
AIRBAG 24P COVER ASSY

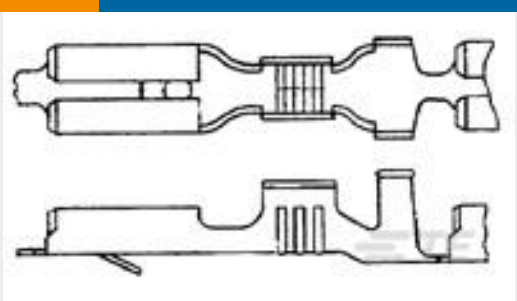


TE Part #170015-2
FF 110 REC 20-16AWG BR REREELING



TE Part #2310537-2
PLUG ASSY, KEY B, CPA, HVA280-2PHI, V0



 TE Part #ASU603-05PN-HE
PLUG ASSY ASU 5 WAY



TE Part #5720254002
FRAG-6/3.5-0-SP



TE Part #1SNA103969R0300
AFSE 100 G ORANGE



TE Part #2066596-1
MICRO RELAY MODULE, 4P, ASSY

Documents



Product Drawings

PL 250 REC TERMINAL 20-17 AWG PTPPB

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_927852-7_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_927852-7_G.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_927852-7_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1654742_HOUSEHOLD_APPLIANCES_RAST5

English

Product Specifications

Application Specification

German

Application Specification

English