




MTA 100

TE Internal #: 641239-5

TE Internal Description: 05P MTA100 CONN ASSY BLU 30AU

Nylon Gold Plated Receptacle: 2.54 mm, no Mating Alignment

[View on TE.com >](#)

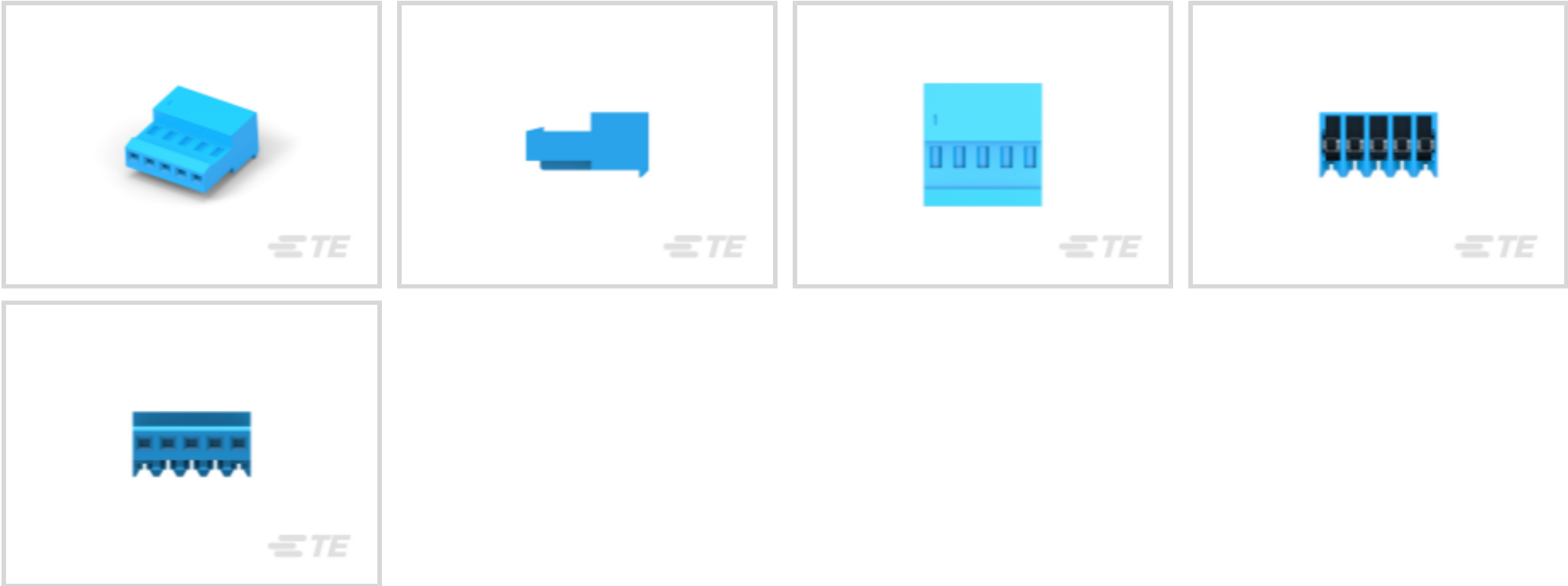

All Nylon Gold Plated Receptacle: 2.54 mm, no Mating Alignment (89)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2022 (224) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Also in the Series | MTA 100

Connector Caps & Covers(69)	Connector Contacts(8)	Connector Hardware(1)	Insertion & Extraction Tools(2)
PCB Headers & Receptacles(441)	Standard Rectangular Connectors(495)	Wire-to-Board Connector Assemblies & Housings(1)	

Customers Also Bought

TE Part #100147-1 HM Receptacle Connector: Traditional Backplane, Coplanar, 2mm	TE Part #1658543-1 SOCKET CONT DUPL PLT LP HD-20	TE Part #640638-3 MTA100 IDC CONTACT L/P 26AWG	TE Part #5352132-1 Z-PACK/B MALE HDR 110P
TE Part #T4145535041-001 M12 R/A F PNL STAMPED PIN D-CODE 4P SHLD	TE Part #5103311-3 A/L LOW PRO HDR 16P RA BLACK	TE Part #1-1586037-2 12P VERT HDR VAL-U-LOK V2	TE Part #2-2176331-0 CRGP 2512 390R 1%
TE Part #6-2176364-9 RQ 0402 23K7 0.1% 10PPM 5K RL			



Documents

Product Drawings

05P MTA100 CONN ASSY BLU 30AU

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_641239-5_AC_c-641239-5-ac.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_641239-5_AC_c-641239-5-ac.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_641239-5_AC_c-641239-5-ac.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Product Specification

English

Agency Approvals

Agency Approval Document

English