


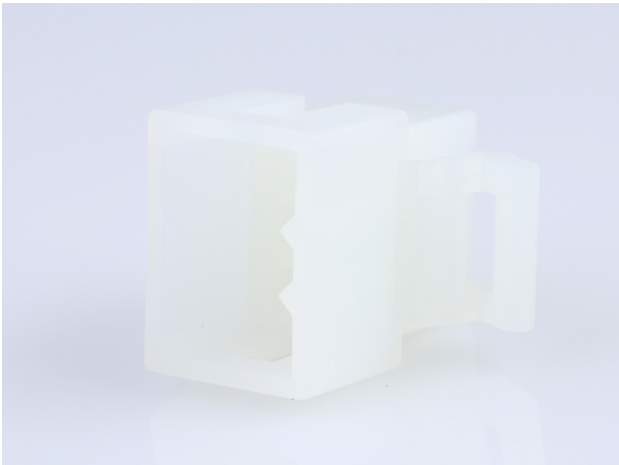

Part Number : [469990804](#)
Product Description : 1.57mm Diameter
Standard .062" Pin and Socket Plug Housing, 6
Circuits, with Pre-bent Mounting Ears, Natural
Series Number : 1625
Status : Active
Product Category : Connector Housings
Engineering Number : 1625-6P2



Documents & Resources

Drawings

[Drawing 469990804_sd.pdf](#)

3D Models and Design Files

[3D Model 469990804_stp.zip](#)

Specifications

[Packaging Specification PK-1625-003-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)4144-DC (27 June 2024)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	1625
Description	1.57mm Diameter Standard .062" Pin and Socket Plug Housing, 6 Circuits, with Pre-bent Mounting Ears, Natural
Application	Power, Wire-to-Wire
Product Family	Standard .062"+ and Standard .062" Pin and Socket Connector Systems
Product Name	Standard .062"
UPC	889056852432

Agency

CSA	LR19980
UL	E29179

Physical

Circuits Detail	2x3
Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-2
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon

Net Weight	1.715/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.68mm
Pitch - Termination Interface	3.68mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C