

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2004850780

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Vertical, 5.60mm Height, 105°C Operating Temperature, 80 Circuits, Gold (Au) Plating, with Ground Terminal

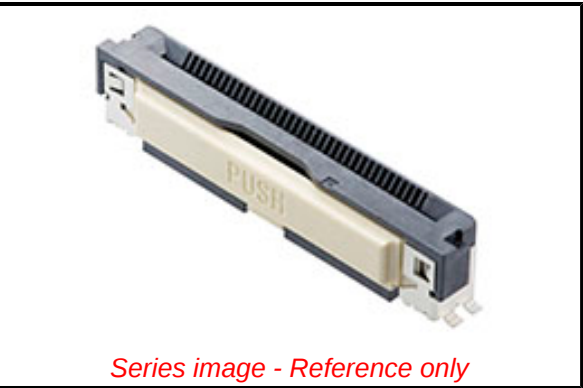

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification 2004851400-PS-000 (PDF)

Packaging Specification 2004859200-SPK-201 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	200485
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	191130074754
Physical	
Actuator Type	One-Touch
Circuits (Loaded)	80
Circuits (maximum)	80
Color - Resin	Black
Contact Position	N/A
Durability (mating cycles max)	20
Mated Height	5.60mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	1322.826/mg
Number of Rows	1
Orientation	Vertical
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FFC/FPC

Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2004859200-SPK-201
Product Specification	2004851400-PS-000
Sales Drawing	2004850700-000, 2004851700-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

200485 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION