



INTERCONNECTS

SERIES 712 • 2,54 GRID CARRIER WITH SOLDER TAIL • SINGLE AND DOUBLE ROW STRIPS

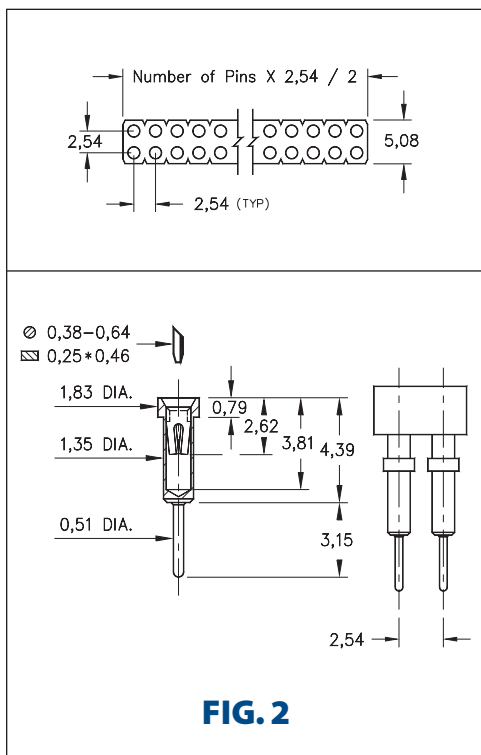

- Standard solder tail receptacles can be mounted as a low profile receptacle or by the solder tail for use in smaller diameter holes
- Series 712 use MM #0255 pins. See page 165 for details
- Hi-Rel, 4-finger BeCu #30 contact is rated at 3 amps. See page 253 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

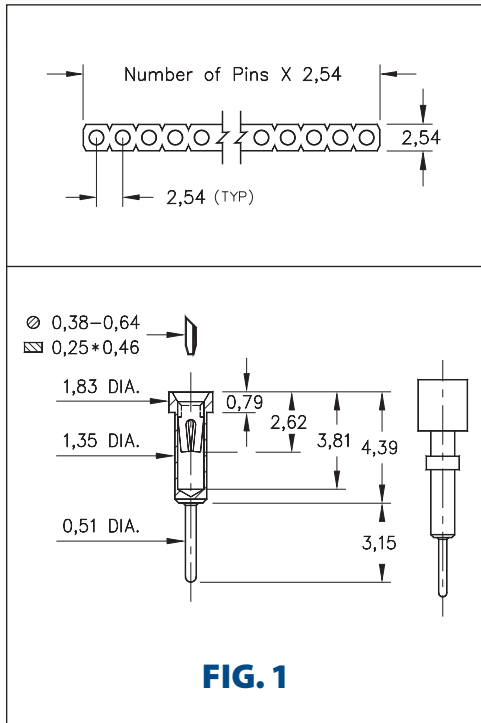

ORDERING INFORMATION

FIG. 1	Single Row (0,71 or 1,4 min. mounting holes)	
	712-XX-1	-41-001000
	Specify number of pins	01-64
FIG. 2	Double Row (0,71 or 1,4 min. mounting holes)	
	712-XX-2	-41-001000
	Specify number of pins	04-64



XX=Plating Code
See Below

For
Electrical, Mechanical
& Environmental Data,
See page 264

SPECIFY PLATING CODE XX=	11	13	91	93	41	43	
Sleeve (Pin)	0,25μm Au	0,25μm Au	5,08μm Sn/Pb	5,08μm Sn/Pb	5,08μm Sn	5,08μm Sn	
Contact (Clip)	0,25μm Au	0,76μm Au	0,25μm Au	0,76μm Au	0,25μm Au	0,76μm Au	



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[712-93-264-41-001000](#) [712-93-164-41-001000](#) [712-93-132-41-001000](#) [712-93-120-41-001000](#) [712-13-264-41-001000](#) [712-13-164-41-001000](#) [712-13-132-41-001000](#) [712-13-120-41-001000](#) [712-43-264-41-001000](#) [712-43-164-41-001000](#) [712-43-132-41-001000](#) [712-43-120-41-001000](#) [712-11-103-41-001000](#) [712-11-160-41-001000](#) [712-13-112-41-001000](#) [712-11-118-41-001000](#) [712-13-103-41-001000](#) [712-13-108-41-001000](#) [712-11-106-41-001000](#) [712-11-110-41-001000](#) [712-11-116-41-001000](#) [712-13-136-41-001000](#) [712-11-150-41-001000](#) [712-41-104-41-001000](#) [712-13-248-41-001000](#) [712-41-131-41-001000](#) [712-43-118-41-001000](#) [712-41-162-41-001000](#) [712-43-122-41-001000](#) [712-43-150-41-001000](#) [712-43-260-41-001000](#) [712-41-236-41-001000](#) [712-91-210-41-001000](#) [712-93-125-41-001000](#) [712-93-252-41-001000](#) [712-93-218-41-001000](#) [712-41-264-41-001000](#) [712-41-164-41-001000](#) [712-91-132-41-001000](#) [712-91-264-41-001000](#) [712-41-132-41-001000](#) [712-11-264-41-001000](#) [712-11-164-41-001000](#) [712-91-164-41-001000](#)