

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2004850240

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Right-Angle, Bottom Contact, 4.46mm Height, 125°C Operating Temperature, 40 Circuits, Gold (Au) Plating, with Ground Terminal

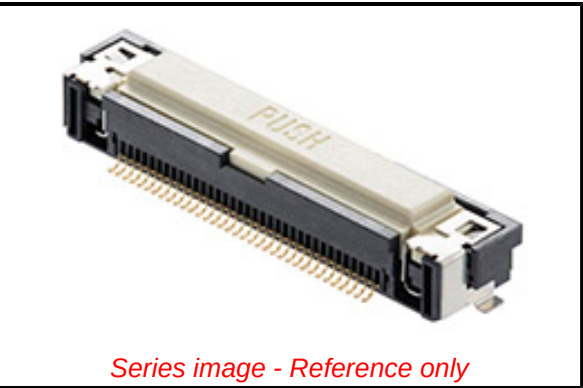

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification 2004851000-PS-000 (PDF)

Packaging Specification 2004859200-SPK-200 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Overview

Product Name

UPC

FFC/FPC Connectors

200485

Easy-On FFC FPC Connectors

Easy-On

191130074204

Physical

Actuator Type

Circuits (Loaded)

Circuits (maximum)

Color - Resin

Contact Position

Durability (mating cycles max)

Mated Height

Material - Metal

Material - Plating Mating

Material - Resin

Net Weight

Number of Rows

Orientation

PCB Mounting

PCB Retention

Packaging Type

Pitch - Mating Interface

Polarized to PCB

Stackable

Temperature Range - Operating

Wire/Cable Type

One-Touch

40

40

Black

Bottom

20

4.46mm

Copper Alloy

Gold

Liquid Crystal Polymer

795.925/mg

1

Right Angle

Surface Mount

Yes

Embossed Tape on Reel

0.50mm

Yes

No

-40° to +125°C

FFC/FPC

Electrical

Current - Maximum per Contact

Voltage - Maximum

0.5A

50V

Material Info

Reference - Drawing Numbers

Packaging Specification

Product Specification

Sales Drawing

2004859200-SPK-200

2004851000-PS-000

2004850200-000, 2004851200-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

200485 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION