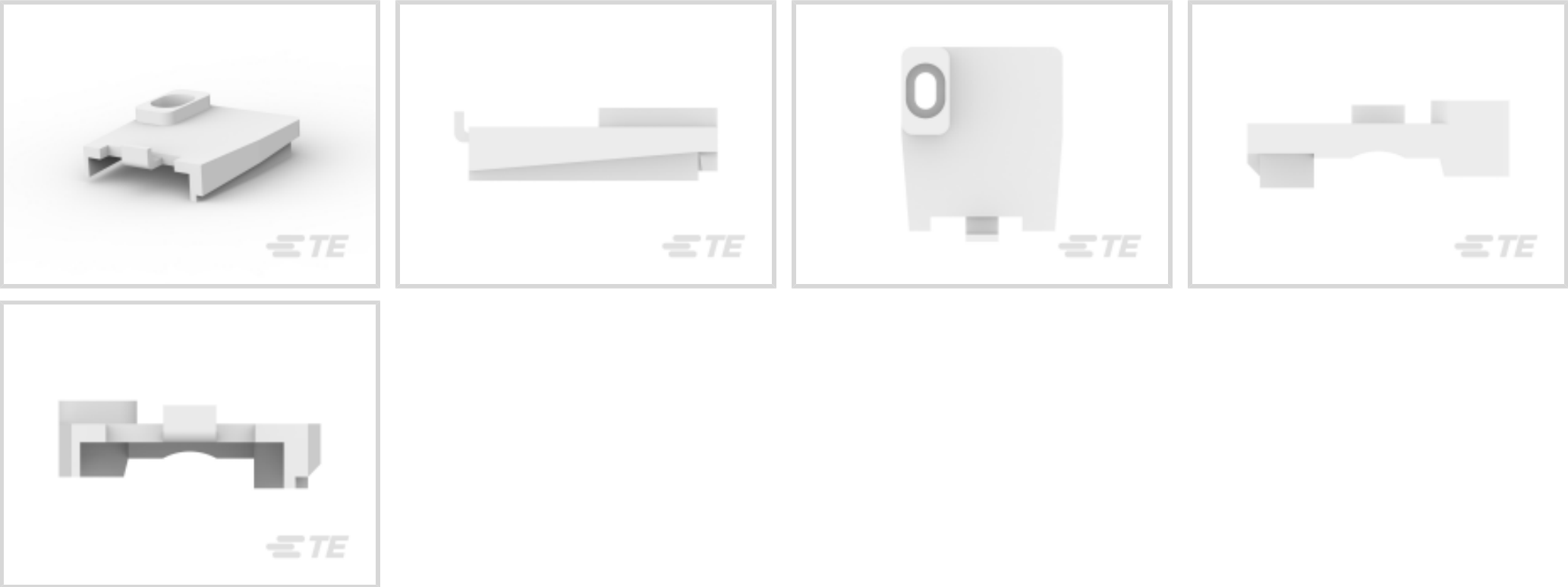




Connectors > Connector Accessories > Connector Caps & Covers



Connector Cover Type: **Strain Relief Cover**

Primary Product Color: **Natural**

Primary Product Material: **Nylon**

Number of Positions: **3**

Operating Temperature (Max): **105 °C [221 °F]**

Features

Product Type Features

Connector Cover Type	Strain Relief Cover
----------------------	---------------------

Configuration Features

Number of Positions	3
---------------------	---

Body Features

Primary Product Color	Natural
Primary Product Material	Nylon

Mechanical Attachment

Strain Relief	With
---------------	------

Usage Conditions

Operating Temperature (Max)	105 °C[221 °F]
Operating Temperature Range	-20 – 105 °C[-4 – 221 °F]

Packaging Features

Packaging Quantity	1
Packaging Method	Package



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 3-643228-0
03P UMNL HDR ASSY R/A 94VO LF

TE Part # 643228-1
03P UMNL HDR ASSY R/A 94VO

TE Part # 3-350943-0
03P UMNL HDR ASSY R/A 94VO LF

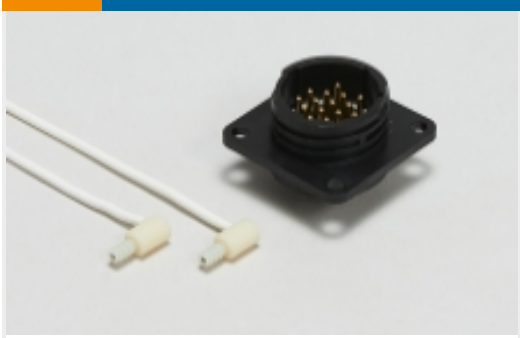
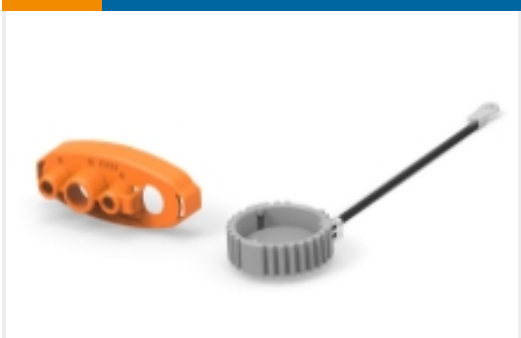
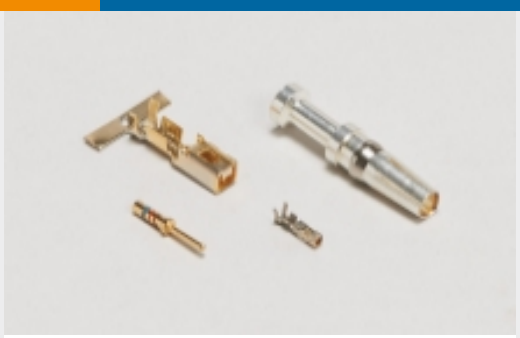
TE Part # 350790-1
03P UMNL PIN HDR ASSY 94VO



 TE Part # 350789-3 03P UMNL PIN HDR ASSY 94VO	 TE Part # 1-350943-0 03P UMNL HDR ASSY R/A 94VO	 TE Part # 641965-1 03P UMNL PIN HDR ASSY V2 NATL	 TE Part # 350789-1 03P UMNL PIN HDR ASSY 94VO
 TE Part # 350760-4 03P UMNL HDR ASSY PC	 TE Part # 350767-1 03P UMNL CAP HSG V0	 TE Part # 350429-1 03P UMNL PIN HDR ASSY NATL	 TE Part # 641966-1 03P UMNL PIN HDR ASSY 94VO
 TE Part # 350766-1 03P UMNL PLUG HSG	 TE Part # 350825-1 03P UMNL HDR ASSY PC 94VO	 TE Part # 643414-3 03P UMNL HDR ASSY POL 94VO LF	 TE Part # 643413-1 03P UMNL HDR ASSY SCKT POL
 TE Part # 643414-1 03P UMNL HDR ASSY POL 94VO	 TE Part # 1-480701-0 03P UMNL CAP HSG NATL	 TE Part # 1-480700-0 03P UMNL PLUG HSG NATL	 TE Part # 350429-4 03P UMNL PIN HDR ASSY NATL LF

Also in the Series

Universal MATE-N-LOK

 Circular Power Connectors(2)	 Connector Caps & Covers(34)	 Connector Contacts(209)	 Connector Hardware(12)
---	---	--	---



Connector Seals & Cavity Plugs(27)

Connector Strain Relief(7)

Insertion & Extraction Tools(4)

Rectangular Connector Housings(1)

Rectangular Power Connectors(670)

Standard Circular Connectors(1)

Customers Also Bought

TE Part #52927-1
PIDG SP SPD 22-16COMM22-18MIL4

TE Part #5745563-3
HD KIT,SCREWLOCK

TE Part #350766-1
03P UMNL PLUG HSG

TE Part #643030-1
05P UMNL STR/REL

TE Part #1-2176389-5
RQ 1206 150R 0.1% 10PPM 5K RL

TE Part #102537-3
10 AMPMODU MT COVER DR .100CL

TE Part #5052994173
RNF-100-1/8-BK-SP

TE Part #929973-1
BU-KONTAKT 2,5MMD

TE Part #1445048-6
PANEL MT SNGL ROW HSG 6 POS

TE Part #CBL-D494D5-10
4 WIRE EXTENSION CABLE 10FT

Documents



Product Drawings

03P UMNL STR/REL

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_640714-1_W.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_640714-1_W.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_640714-1_W.3d_stp.zip

English

Customer View Model

ENG_CVM_640714-1_C1.3d_igs.zip

English

Customer View Model

ENG_CVM_640714-1_C1.3d_stp.zip

English

Customer View Model

ENG_CVM_640714-1_C1.2d_dxf.zip

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

SOFT_SHELL_PIN_SOCKET_CONNECTORS_STANDARD_DENSITY

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English