




SMD Pulse Transformer

- 1.SMD type pulse transformers.
- 2.Inductance and common mode rejection components
- 3.DWC321622NF is small size and low profile
- 4.100% Lead(Pb) & Halogen-Free and RoHS compliant.
- 5.Operating temperature -40~ +85 C


Part Number	Electrical Specifications@25°C								
	Inductance 100KHz 0.1V (uH Min) 1-4 or 2-3	Inductance 100KHz 0.1V (uH Min) 3-4 or 1short2	DCR (Ω Max)	Insertion Loss (dB Max)	Return Loss (dB Min) 100M	Rated Current mA Max	Rated Volt (Vdc)	Common mode Impedance (ohm ±25%@100M) 3-4 to 6-5	IR M(Ω Min)
DWC321622NF-601	55	220	3.2	-1.5	-10	200	50	600	10

MECHANICAL

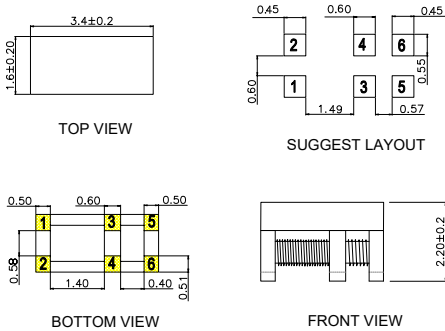


Unless otherwise specified all tolerances are ±0.10mm


SCHEMATICS

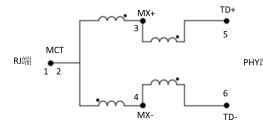

IMPEDEANCE FREQUENCY

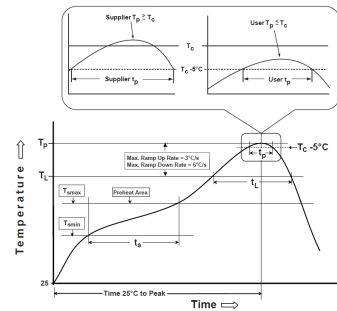


TAPING AND PACKING

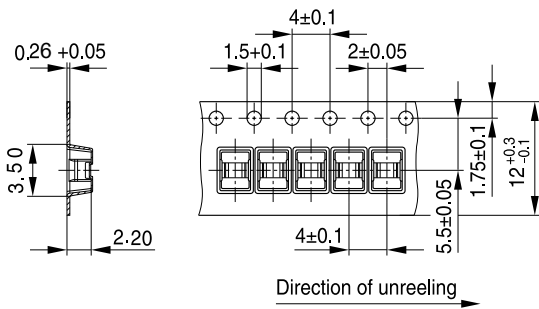

IND1752-J-E

Reel

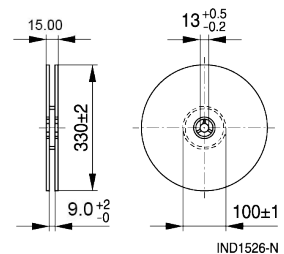

Dimensions in mm

Quantity (pcs):
 3000 PCS PER REEL
 10 REELS PER CARTON
 30000PCS PER CARTON