

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2004850030

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Right-Angle, Bottom Contact, 4.46mm Height, 125°C Operating Temperature, 30 Circuits, Gold (Au) Plating

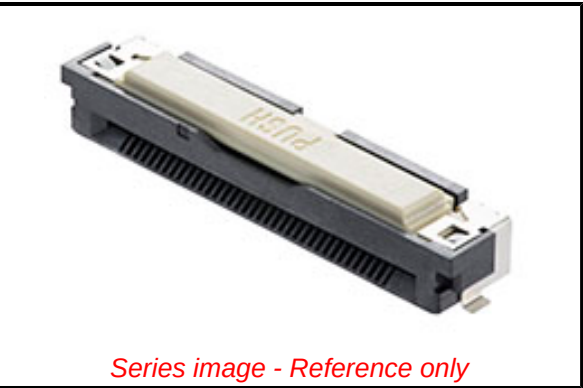

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification 2004851000-PS-000 (PDF)

Packaging Specification 2004859200-SPK-200 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	200485
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	191130073887
Physical	
Actuator Type	One-Touch
Circuits (Loaded)	30
Circuits (maximum)	30
Color - Resin	Black
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	4.46mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	650.488/mg
Number of Rows	1
Orientation	Right Angle
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2004859200-SPK-200
Product Specification	2004851000-PS-000
Sales Drawing	2004850000-000, 2004851000-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

200485 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION