

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2004850235

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC One-Touch Connector, 0.50mm Pitch, Right-Angle, Bottom Contact, 4.46mm Height, 125°C Operating Temperature, 35 Circuits, Gold (Au) Plating, with Ground Terminal

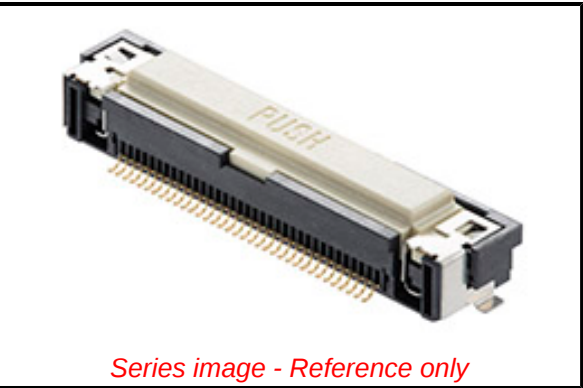

Series image - Reference only

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification 2004851000-PS-000 (PDF)

Packaging Specification 2004859200-SPK-200 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	200485
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
UPC	191130074198
Physical	
Actuator Type	One-Touch
Circuits (Loaded)	35
Circuits (maximum)	35
Color - Resin	Black
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	4.46mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	702.254/mg
Number of Rows	1
Orientation	Right Angle
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +125°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2004859200-SPK-200
Product Specification	2004851000-PS-000
Sales Drawing	2004850200-000, 2004851200-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

200485 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION