

AI 16 -18 GN - Ferrule

3201330

<https://www.phoenixcontact.com/us/products/3201330>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Ferrule, sleeve length: 18 mm, color: green

Your advantages

- The ferrules with plastic sleeve are made from soft tin-plated electrolytic copper
- The AI 0,25... can also be used to process 0.14 mm² conductors
- In terms of dimensions, they correspond to DIN 46228-4: 1990-09

Commercial data

Item number	3201330
Packing unit	100 pc
Minimum order quantity	100 pc
Sales key	BH34
Product key	BH3411
Catalog page	Page 483 (C-3-2019)
GTIN	4017918094836
Weight per piece (including packing)	0.95 g
Weight per piece (excluding packing)	0.95 g
Customs tariff number	85369010
Country of origin	DE

AI 16 -18 GN - Ferrule



3201330
<https://www.phoenixcontact.com/us/products/3201330>

Technical data

Product properties

Product type	Cable end sleeve
Conductor category	stranded conductors, class 2, 5, 6 / B, C, K, M

Data management status


Article revision	05
------------------	----

Connection data

Conductor connection

Conductor cross section flexible max.	16 mm ²
Conductor cross section AWG max.	6
Stripping length	22 mm

Dimensions

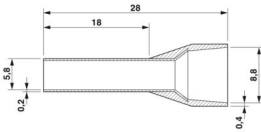Dimensional drawing	
Sleeve length	18 mm
Maximum stripping length	22 mm
Ferrule diameter	5.8 mm
Sleeve wall thickness	0.2 mm
Insulating collar thickness	0.4 mm
Inner dimensions of the insulating collar	8.8 mm

Material specifications

Color	green (RAL 6021)
Material	CU-DHP
Flammability rating according to UL 94	HB
Coating	tin-plated (galvanic)
Components	free from silicone and halogen

Mechanical properties

Technical data

Sleeve length	18 mm
---------------	-------

Environmental and real-life conditions

Ambient conditions

Permanent temperature	105 °C (-40 °C no load / 0 °C dynamic load)
Short-term temperature	120 °C

AI 16 -18 GN - Ferrule



3201330

<https://www.phoenixcontact.com/us/products/3201330>

Standards and regulations

Design according to standard	Special color
------------------------------	---------------

Mounting

Thread type	()
-------------	----

AI 16 -18 GN - Ferrule


3201330

<https://www.phoenixcontact.com/us/products/3201330>



Drawings

Dimensional drawing

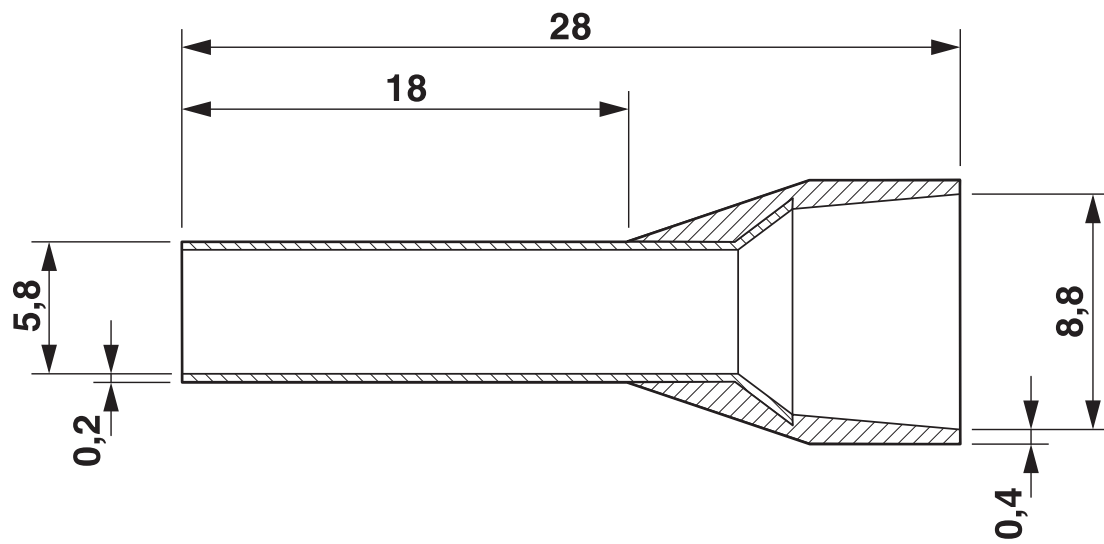

AI 16 -18 GN - Ferrule

3201330

<https://www.phoenixcontact.com/us/products/3201330>



Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/3201330>



cULus Listed

Approval ID: E488001

AI 16 -18 GN - Ferrule



3201330

<https://www.phoenixcontact.com/us/products/3201330>

Classifications

ECLASS

ECLASS-11.0	27400201
ECLASS-13.0	27400201
ECLASS-12.0	27400201

ETIM

ETIM 9.0	EC000005
----------	----------

UNSPSC

UNSPSC 21.0	27121700
-------------	----------

AI 16 -18 GN - Ferrule



3201330
<https://www.phoenixcontact.com/us/products/3201330>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2024 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com