

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190710179
Status: Active
Overview: Solderless Terminals
Description: InsulKrimp Ring Tongue Terminal for 8 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-015-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19071
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name InsulKrimp
Type Ring
UPC 800753071452

Physical

Barrel Type Closed
Color - Resin Natural
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 3.425/g
Packaging Type Adhesive Tape on Reel
Stud Size 8 (M4)
Wire Insulation Diameter 6.70mm max.
Wire Size AWG 8
Wire Size mm² 6.60-10.50

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number D-656-08XT

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001,
PS-19902-015-001
Sales Drawing SD-19071-002

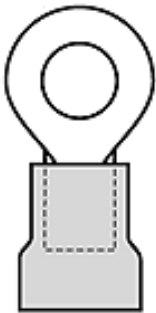

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
Prop65	Missing Compliance
	Data
RoHS Phthalates	Not Contained

Search Parts in this Series

19071 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION