



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Connector Product Type: **Connector Assembly**
Operating Voltage: **250 VDC**
Connector System: **Wire-to-Board, Wire-to-Panel**
Number of Positions: **4**
Sealable: **Yes**

Features

Product Type Features

Connector Product Type	Connector Assembly
Connector System	Wire-to-Board, Wire-to-Panel
Sealable	Yes
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Configuration Features

Number of Positions	4
Number of Power Positions	0
Number of Signal Positions	4

Electrical Characteristics

Operating Voltage	250 VAC
-------------------	---------

Contact Features

Reverse Gender	No
Contact Type	Pin

Termination Features

Termination Method to PCB	Through Hole - Solder
---------------------------	-----------------------

Mechanical Attachment

Mating Alignment Type	Keyed
-----------------------	-------



Mating Alignment	With
Panel Mount Feature Type	Flange with Mounting Holes
Mating Retention Type	Threaded Coupling
Polarization Code	A
Connector Mounting Type	Panel Mount
Mating Retention	With
Panel Mount Feature	With

Housing Features

Housing Color	Black
Housing Material	PA 6.6
Circular Connector Shell Size	11

Dimensions

Assembly Length	39.37 mm[1.55 in]
-----------------	-------------------

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	Immersion

Operation/Application

Circuit Application	Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	27
Packaging Method	Tray

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241)



Candidate List Declared Against: JUNE 2024 (241)
Does not contain REACH SVHC

Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 206060-2
CPC PLUG,SZ 11-4,SMALL PACK

Also in the Series | AMP CPC

Circular Power Connectors(458)

Connector Backshells(1)

Connector Caps & Covers(19)

Connector Contacts(6)



Connector Hardware(12)



Connector Seals & Cavity Plugs(36)



Connector Strain Relief(60)



Insertion & Extraction Tools(1)



Sealing Sleeves(2)

Customers Also Bought



TE Part #1-5747299-4
15 RCPT SP/FMS SCRLK



TE Part #1-5745967-4
25 RCPT SP/FMS SCRLK



TE Part #1-5747872-6
15 PLUG SP/FMS INSRT



TE Part #1744416-6
6 POS EP II HSG, GLOW WIRE




TE Part #3-520404-2
ULTRA-FAST 187 ASY REC 16-14 AWG TPBR



TE Part #1744201-1
EP-II CONTACT LANCELESS, 20-16



TE Part #1-826629-6
16X1 AMPMODU II HDR ST

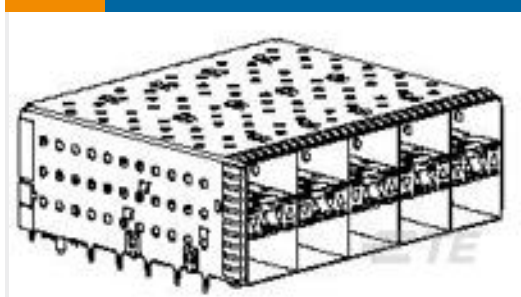

TE Part #2132403-5
2X5 SFP+ w/ Springs, 4 LP Sn



TE Part #6600150-1
MBXL R/A HDR DB 4P+24S

Documents



CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-207825-5_AG.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-207825-5_AG.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-207825-5_AG.3d_stp.zip

English

3D PDF

English

Customer View Model

ENG_CVM_1-207825-5_R1.2d_dxf.zip

English

Customer View Model

ENG_CVM_1-207825-5_R1.3d_igs.zip

English

Customer View Model

ENG_CVM_1-207825-5_R1.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Connector, Circular Plastic

English

Product Specification

English

Agency Approvals

CSA Certificate

English

CSA Certificate

English