


Coaxial PCB Connector 85_BNC-50-0-1/111_N

Description

Right angle PCB jack

Interface Standards

IEC 60169-8_MIL-STD-348A/301_CECC 22120

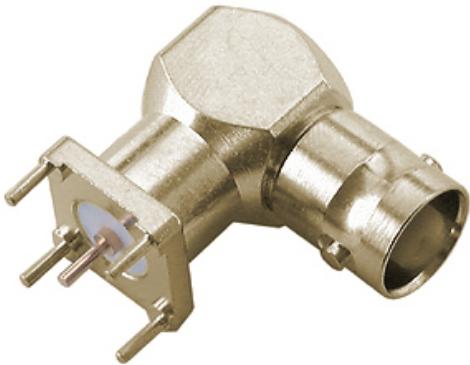

Technical Data

Electrical Data

Impedance	50 Ω
Interface frequency max.	4 GHz

Mechanical Data

Board mounting type	through holes
Weight	0.0185 kg

Environmental Data

Operating temperature	-65 °C to 165 °C
2011/65/EU (RoHS - including 2015/863 and 2017/2102)	compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium / Brass	SUCOPRO Plating
Outer contact	Brass	SUCOPRO Plating
Body	Brass	SUCOPRO Plating
Insulator	PFA / PTFE	

Related Documents

Outline drawing	DOU-00070952
Catalogue drawing	DCA-00012658
Mounting hole	DOU-00012084

Ordering Information

Single package	85_BNC-50-0-1/111_NE
----------------	----------------------

Remarks

PCB connector with stand-offs