



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Not Compliant
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2023 (235) SVHC > Threshold: Pb (13% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not lead free process capable

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # 794894-1 02P MINI UMNL PLUGS WIRE HOLES	TE Part # 794772-2 02P MINI UMNL SEAL,DIE CUT	TE Part # 172165-1 2 CIR UNIV M-N-L PLUG NATL	TE Part # 794184-1 02P MINI UMNL2 PLUG HSG UL94V0


Also in the Series | Mini-Universal MATE-N-LOK

Connector Caps & Covers(2)	Connector Contacts(89)	Connector Hardware(4)	Connector Seals & Cavity Plugs(17)
Connector Strain Relief(2)	Insertion & Extraction Tools(1)	Rectangular Power Connectors(197)	

Customers Also Bought

TE Part #5745072-2 HD-20 PLUG 15P VERT FFSCRLK	TE Part #5745079-4 HD-20 RCPT 37P VERT FFSCRLK	TE Part #350789-1 03P UMNL PIN HDR ASSY 94VO	TE Part #172165-1 2 CIR UNIV M-N-L PLUG NATL



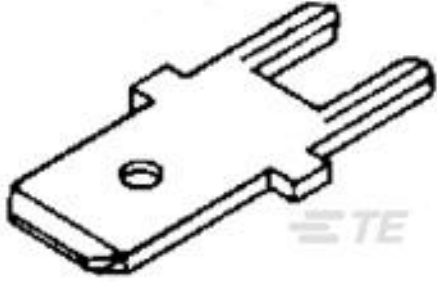


TE Part #726386-2
250 FASTON TAB TPBR




TE Part #1-1437601-8
PICOD137AK2=BCD COMPLEMENT SW



TE Part #770986-3
MINI UMNL SOK 26-22AWG AU LP

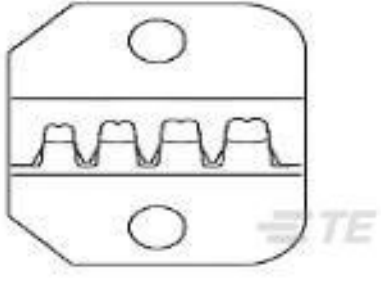

TE Part #91909-1
PREM SDE DIE,BNC COAXICON

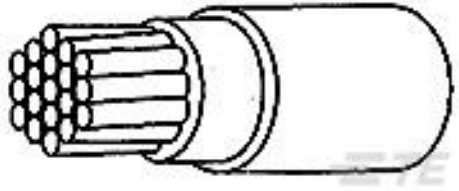

TE Part #6469533001
FLT0111-0.25-5



TE Part #9-1478240-0
SDE SA PEW12 HAND TOOL FRAME- NO DIES

Documents

Product Drawings

02P MINI UMNL HDR ASSY SN

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_770872-1_H.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_770872-1_H.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_770872-1_H.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

SOFT_SHELL_PIN_AND_SOCKET_CONNECTORS_CATALOG

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)



English

[Instruction Sheet \(U.S.\)](#)

English

[Agency Approvals](#)

[Agency Approval Document](#)

English