



Since 1959


Product Information Sheet

896 12V 37.5W

896

2010. 12. 13 NEW

2009. 09. 09 OLD

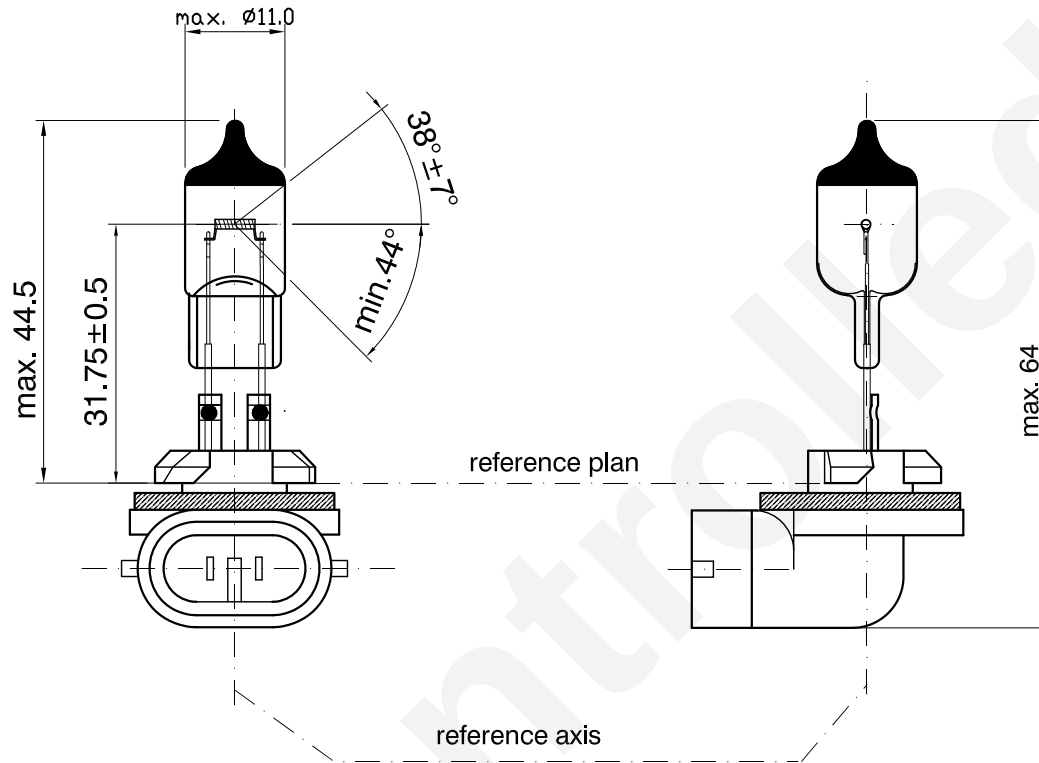

* all dimensions in mm

Halogen bulb

896 12V 37.5W

Cap: ¹⁾ PGJ13

Type: 896

ECE R37 none

FMVSS108 none

Bulb mat.: UV-cut Hardglass

Made in Korea / INCHON

1) according to IEC 61-1 sheet 7004-107-1

2) Without black top

Technical data	
Test voltage	12.8V
Power	43W max
Luminous flux	²⁾ 940lm ±15%
Lumen maintenance	85 % min
Rated life:	at 14.0V - Average 200 hr

Maximum operating temperature:	bulb 650°C max pinch 400°C max
Operating position	horizontal