

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191180090](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Flanged Spade Tongue Terminal for 10-12 AWG Wire, Stud Size 10 (M5), Length 19.56mm, Mylar Tape Carrier

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19118](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Spade
UPC 800753093881

Physical

Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 2.232/g
Packaging Type Adhesive Tape on Reel
Stud Size 10 (M5)
Wire Size AWG 10, 12
Wire Size mm² 4.00-6.00

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number C-117-10T

Reference - Drawing Numbers

Product Specification PS-19902-011-001, PS-19902-015-001
Sales Drawing SD-19118-002

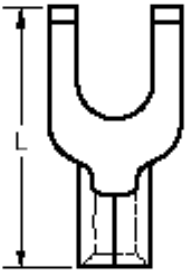

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19118 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION